

Rittal – The System.

Faster – better – everywhere.



SV 3073.000 Busbar support

State: 18.04.2026. (Source: rittal.com/hr-hr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 3073.000 - Busbar support

For busbar systems 1250 A (100 mm), 1600 A (185 mm), 2500 A (150 mm), 3000 A (150 mm).

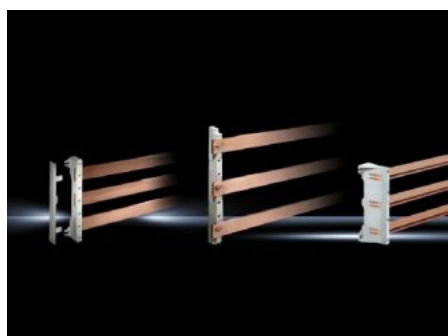

Features

Model No.	SV 3073.000
Material	Fibreglass-reinforced, thermoplastic polyester (PBT) Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Number of poles	3-pole 100 mm
To fit busbars	30 x 10 40 x 10 50 x 10 60 x 10
Rated current max.	1.250 A
Dimensions	Width: 22 mm Height: 320 mm Depth: 70 mm
Packs of	4 pc(s).
Net weight	1,612 kg
Gross weight	1,83 kg
Customs tariff number	85469010
ETIM 9	EC001166
ETIM 8	EC001166

Features

ECLASS 8.0	27400607
------------	----------

Product description	SV Busbar support, 3-pole, 100 mm bar centre distance, for busbar WH: 30-60x10 mm
---------------------	--

Approvals

Explanations	Declaration of conformity Declaration of conformity UK
--------------	---

Tender text

SV busbar support
for accommodating busbars. 3-pole busbar support
with 100 mm bar centre distance.
Rated operating voltage: 1000 V~, 50/60 Hz
to VDE 0660
Rated current: up to 1250 A
Material: PBT
Fire protection: UL 94-V0
Continuous operating temperature: 140 °C
Bar centre distance: 100 mm
Bar accommodation without inserts: 60 x 10 mm
Tightening torques
Assembly screws: 8 - 10 Nm
Lid attachment: 1 - 3 Nm
Approvals:
DNV, GL, VDE, ÖVE, SEV, KEMA