
 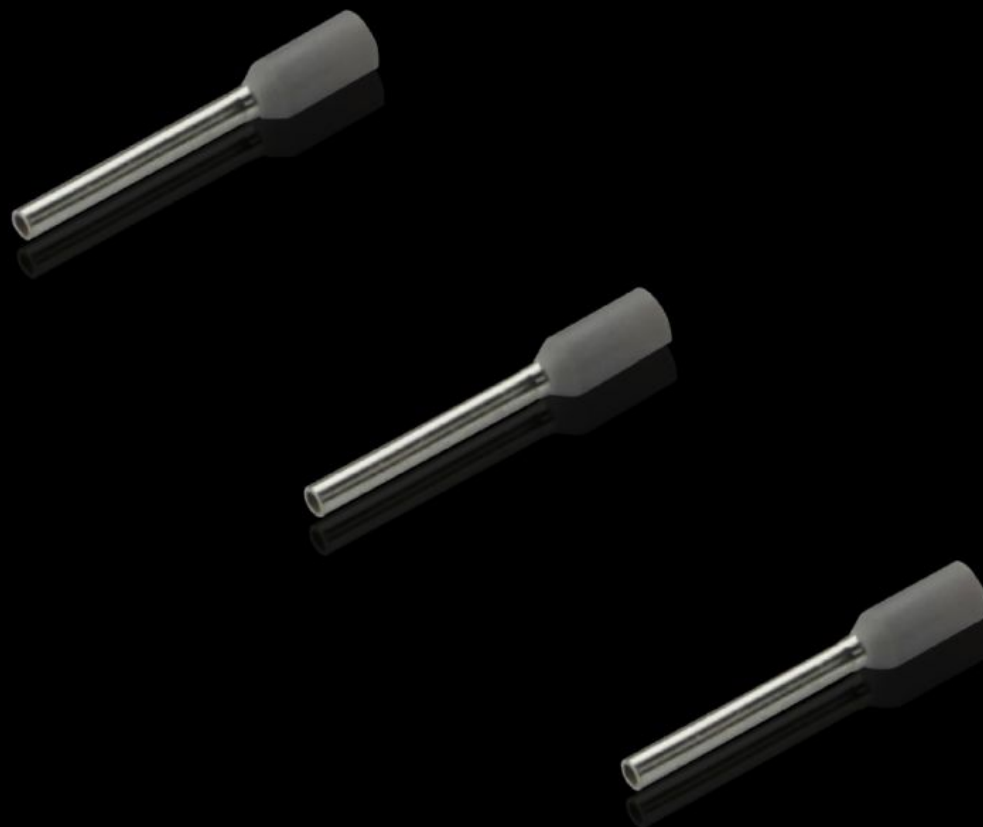


# Rittal – The System.

Faster – better – everywhere.



## AS 4050.752 Wire end ferrules

State: 27.06.2026. (Source: [rittal.com/hr-hr](http://rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.752 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.752
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Grey
Length	8 mm
AWG	26
Internal diameter	1,5 mm
Rittal colour code	Yes
For cross-section	0,14 mm <sup>2</sup>
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
Delivery form	Loose
Packs of	500 pc(s).
Net weight	0,5 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005
ECLASS 8.0	36659290
Product description	Wire end ferrules for manual preassembly, 0.14 mm <sup>2</sup> , AWG 26, 8 mm, grey, loosely packed, 500 pc(s).

# Approvals

---

Approvals

UL + C-UL (listed)

UR