


# Rittal – The System.

Faster – better – everywhere.

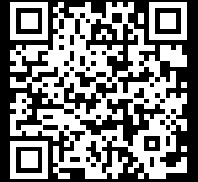

## AS 4050.785 Wire end ferrules

State: 04.04.2026. (Source: [rittal.com/hr-hr](http://rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.785 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.785
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Black
Length	12 mm
AWG	10
Internal diameter	6,3 mm
Rittal colour code	Yes
For cross-section	6 mm <sup>2</sup>
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
To fit Model No.	4051.210
Delivery form	Loose
Packs of	100 pc(s).
Net weight	0,1 kg
Gross weight	0,04 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0

36659290

---

Product description

Wire end ferrules for wire processing, 6 mm<sup>2</sup>, AWG 10, 12 mm, black, loose, 100 pcs.

# Approvals

---

Approvals

UL + C-UL (listed)  
UR