


Rittal – The System.

Faster – better – everywhere.

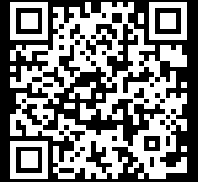

AS 4051.525 Wire end ferrules

State: 05.06.2026. (Source: rittal.com/hr-hr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.525 - Wire end ferrules loose

With plastic collar.

Features

Model No.	AS 4051.525
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Blue
Length	10 mm
AWG	14
Internal diameter	4,2 mm
For cross-section	2,5 mm ²
DIN colour code	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
To fit Model No.	4051.205 4051.210
Delivery form	Loose (10 packs of 100)
Packs of	1.000 pc(s).
Net weight	1 kg
Gross weight	0,176 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005

Features

ECLASS 8.0	36659290
------------	----------

Product description	Wire end ferrules for wire processing, 2.5 mm ² , AWG 14, blue, 10 mm, loose (10 packs of 100), 1000 pcs.
---------------------	--

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------