

Rittal – The System.

Faster – better – everywhere.



DK 5502.025

Fan mounting plate

State: 18.03.2026. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 5502.025 - Fan mounting plate for VX IT, TS IT, TX CableNet

For active ventilation of the VX IT, TS IT or TE 8000, depending on the version.

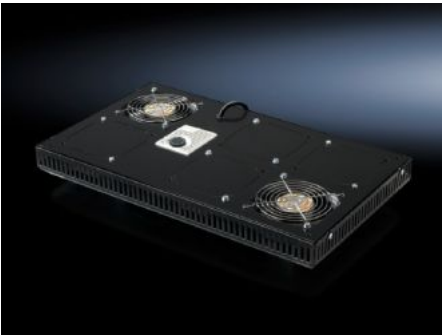

Features

Model No.	DK 5502.025
Product description	For active ventilation. The unit may optionally be extended with additional fans.
Applications	For use in the cut-out integrated into the roof plate
Colour	RAL 9005
Supply includes	1 fan unit 2 fans 1 thermostat Connection cable, open-ended Assembly parts
Dimensions	Width: 340 mm Height: 59 mm Depth: 550 mm
Note	The noise level given refers to the first fan Connection via distributor box or country-specific connector

Features

To fit	Enclosure type: VX IT TS IT Width: 800 mm 800 mm 800 mm Depth: 800 mm 1,000 mm 1,200 mm
Packs of	1 pc(s).
Gross weight	4,8 kg
Customs tariff number	84149000
ECLASS 8.0	27189272
Product description	DK Fan mounting plate, for use in the roof plate, incl. 2 fans, may be expanded to up to 6 fans max., WHD: 340x59x550 mm

Approvals

Explanations	Declaration of conformity UK
--------------	------------------------------