

**Rittal – The System.**

Faster – better – everywhere.



**DK 7119.140**

**Component shelf 1 U, static  
installation**

State: 26.06.2026. (Source: [rittal.com/hr-hr](http://rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7119.140 - Component shelf 1 U, static installation 482.6 mm (19") system punchings

482.6 mm (19")/535 mm (metric), support surface for small active components such as modems or mini-hubs in 482.6 mm (19") or metric levels, load capacity: 10 kg.

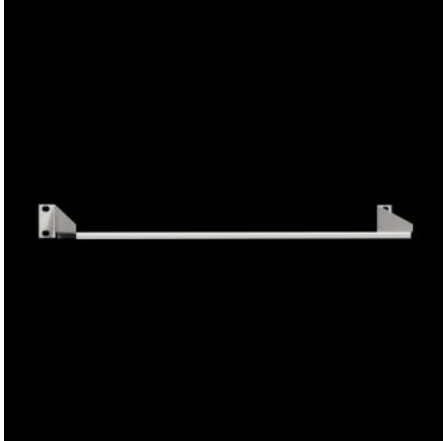

## Features

Model No.	DK 7119.140
Design	482.6 mm (19") version
Product description	The ideal support surface for small active components such as modems or mini-hubs.
Material	Sheet steel
Colour	RAL 7035
Load capacity	10 kg surface load, static
Note	Not suitable for combination with telescopic slides. Free installation height inside the U approx. 35 mm
Dimensions	Width: 482.6 mm Depth: 140 mm
Packs of	1 pc(s).
Net weight	0,781 kg
Gross weight	0,881 kg
PCF per pack (cradle-to-gate)	3.2 kg CO2 eq (Cat B)

# Features

Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910
ETIM 9	EC002620
ECLASS 8.0	27189261
Product description	DK Component shelf, WHD: 482,6x1 Ux140 mm, 10 kg, static, distance between levels:, static installation, For 482.6 mm (19") system punchings, RAL 7035

## Tender text

482.6 mm (19 inch) single-level component shelf,  
D: 140 mm

Load capacity: 10 kg surface load, static

Material: Sheet steel, spray finished in RAL 7035