


# Rittal – The System.

Faster – better – everywhere.

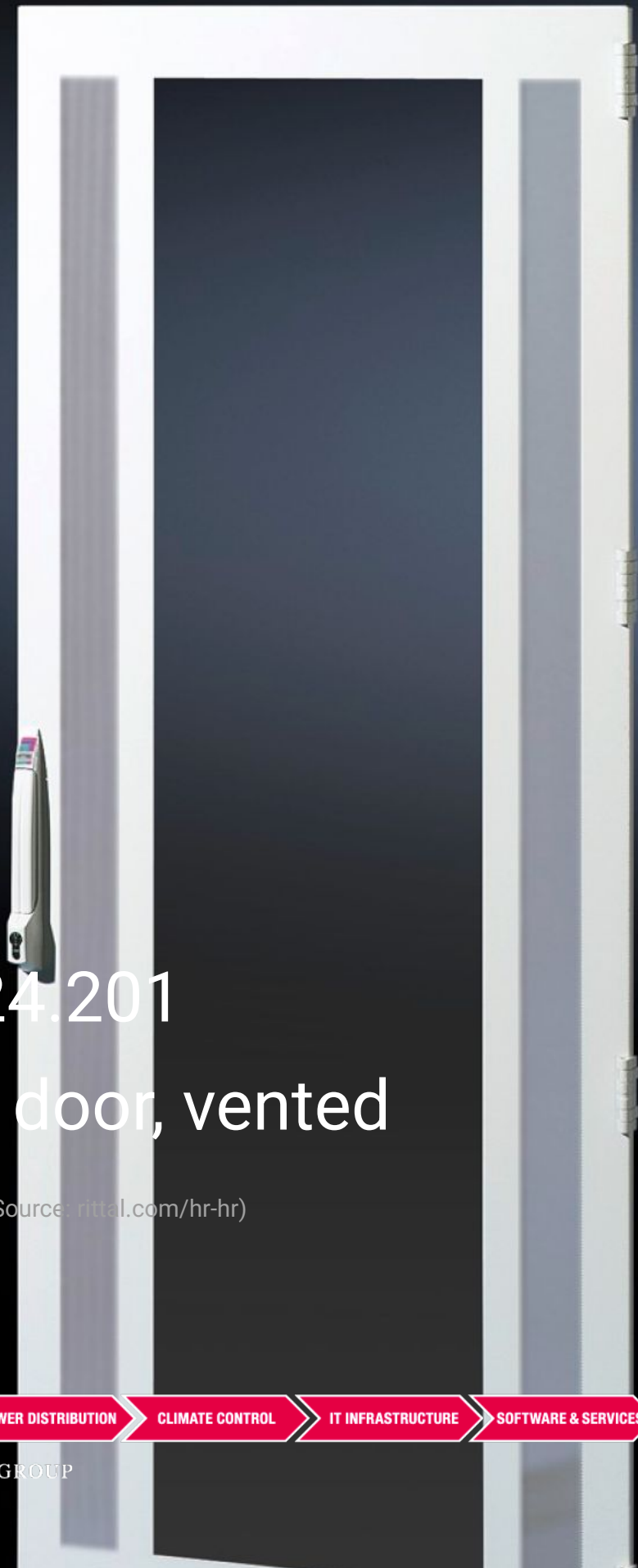

## DK 7824.201 Glazed door, vented

State: 05.06.2026. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

# DK 7824.201 - Glazed door, vented for TS, TS IT, VX SE

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

## Features

Model No.	DK 7824.201
Product description	Surface perforated on both sides with air inlet openings > 78% for optimum air throughput.
Material	Door: Sheet steel Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Colour	RAL 7035
Supply includes	Glazed door, vented Comfort handle for profile half-cylinders with security lock 3524 E 180° hinges (4) Assembly parts
Assembly instruction	For TS enclosure suites with sheet steel doors, only the 180° hinge 7824.520 may be used.
To fit	Enclosure type: TS TS IT SE Width: 600 mm Height: 2,000 mm
Packs of	1 pc(s).
Net weight	19,38 kg
Gross weight	20,4 kg
Customs tariff number	94039910
ETIM 9	EC000747
ECLASS 8.0	27182204
Product description	DK-TS Glazed door, WxH: 600x2000 mm, Vented

# Tender text

Glazed door, vented, for TS

Glazed door, vented, made from 1.5 mm sheet steel with side slotted surfaces in RAL 7035, with foamed-in seal, 180° hinges, 3 mm thick single-pane safety glass, 4-point latch locking rod, comfort handle with security lock no. 3524 E. A semi-cylinder (40/45 mm) to DIN 18254 may be inserted.

Hinges with captive hinge pins, door hinge may be swapped from right to left without dismantling locking rods. Door opening angle 180°.

Material: Sheet steel

Pane: Safety glass, 3 mm

Colour:

Frame: RAL 7035

Pane: Tinted, parsol grey

Dimensions: For enclosures (WxH): W: 600 mm H: 2000 mm