
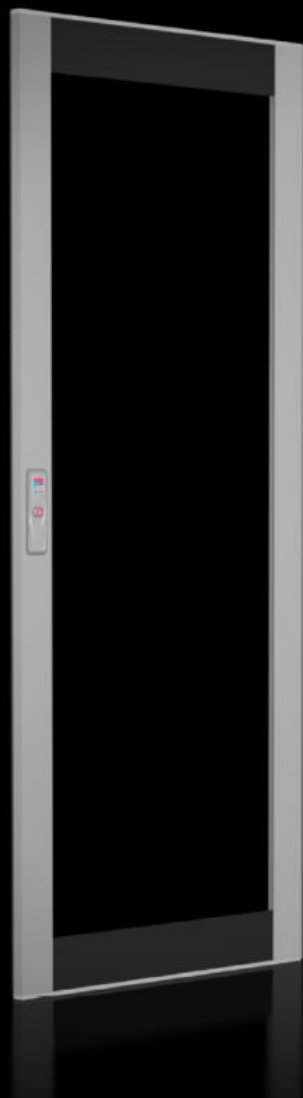


# Rittal – The System.

Faster – better – everywhere.

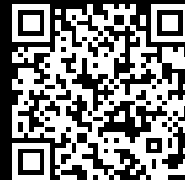

## VX 8618.000 Glazed door

State: 01.09.2025. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 8618.000 - Glazed door for VX

Instead of a sheet steel door or rear panel.

## Features

|                                     |   |
|-------------------------------------|---|
| Model No.                           | VX 8618.000   |
| Product description                 | Instead of a sheet steel door or rear panel.  |
| Material                            | Frame: Extruded aluminium section<br>Viewing window: Single-pane safety glass, 3 mm     |
| Surface finish                      | Powder-coated   |
| Colour                              | Frame: RAL 7035<br>Viewing window (printed mask on the inside): RAL 9005                |
| Supply includes                     | Glazed door<br>Locking rod with double-bit insert<br>180° hinges (4)                    |
| IK Code                             | IK08  |
| Note                                | Lock components for frame 8618.110 are required when mounting instead of the rear panel |
| Type rating to UL 50E               | Type 1<br>Type 12   |
| IP protection category to IEC 60529 | IP 55   |
| To fit                              | Enclosure type: VX<br>Width: = 600 mm<br>Height: = 1,800 mm                             |
| Packs of                            | 1 pc(s).  |
| Net weight                          | 12.4  |
| Gross weight                        | 13  |
| EAN                                 | 4028177921085   |
| ETIM 9                              | EC000747  |
| ECLASS 8.0                          | 27182204  |

# Approvals

|              |                     |
|--------------|---------------------|
| Approvals    | UL + C-UL - FTTA    |
| Certificates | Protection category |