


# Rittal – The System.

Faster – better – everywhere.

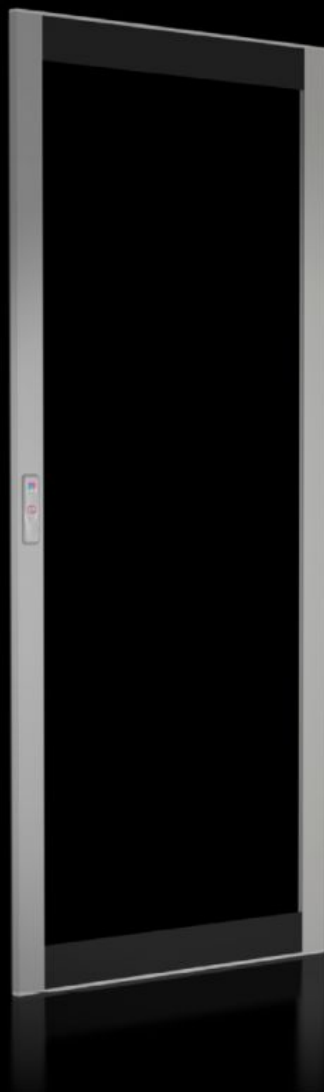

## VX 8618.050 Glazed door

State: 22.05.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 8618.050 - Glazed door for VX

Instead of a sheet steel door or rear panel.

## Features

Model No.	VX 8618.050
Product description	Instead of a sheet steel door or rear panel.
Material	Frame: Extruded aluminium section Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Colour	Frame: RAL 7035 Viewing window (printed mask on the inside): RAL 9005
Supply includes	Glazed door Locking rod with double-bit insert 180° hinges (4)
IK Code	IK08
Note	Lock components for frame 8618.110 are required when mounting instead of the rear panel
Type rating to UL 50E	Type 1, 12
IP protection category to IEC 60529	IP 55
To fit	Enclosure type: VX Width: = 800 mm Height: = 2,200 mm
Packs of	1 pc(s).
Weight/pack	18,8 kg
EAN	4028177921023
ETIM 7.0	EC000747
ECLASS 8.0	27182204

# Approvals

---

Approvals	UL + C-UL (listed) UL + C-UL - FTTA
-----------	--

---

Certificates	Protection category
--------------	---------------------