


# Rittal – The System.

Faster – better – everywhere.

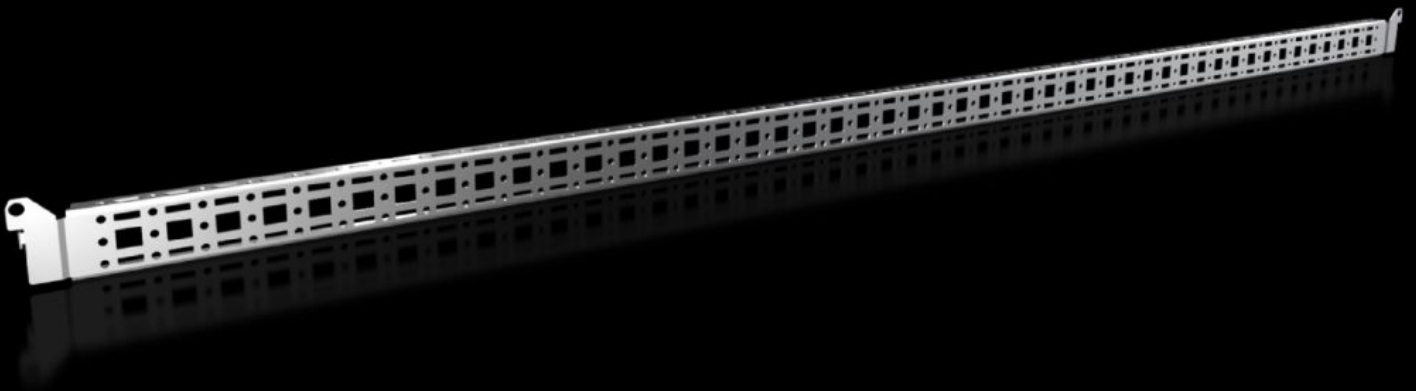

## VX 8619.780

# Punched section with mounting flange, 14 x 39 mm

State: 02.04.2026. (Source: [rittal.com/hr-hr](http://rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 8619.780 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.



## Features

Model No.	VX 8619.780
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	1.275 mm
AX installation options	In enclosure height 1400 mm, in conjunction with rail for interior installation AX
AX stainless steel installation options	In enclosure height 760 mm
Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required

# Features

---

To fit	Enclosure type: AX Suitable for width or height or depth: 1,400 mm
Packs of	4 pc(s).
Net weight	2,44 kg
Gross weight	2,7 kg
Customs tariff number	73269098
ETIM 9	EC002620
ECLASS 8.0	27189234
Product description	VX Punched section with mounting flange, 14 x 39 mm , for H: 1400 mm

# Approvals

---

Explanations	PCF-declaration
--------------	-----------------