


Rittal – The System.

Faster – better – everywhere.

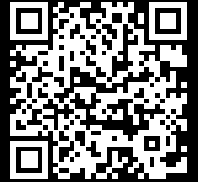

SV 9615.100

Mini-PLS component adaptor

State: 06.05.2026. (Source: rittal.com/hr-hr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 9615.100 - Mini-PLS component adaptor

Maximum rated current from 12 A to 100 A.

Features

| | |
|------------------------------|---|
| Model No. | SV 9615.100 |
| Material | Polyamide Fire protection corresponding to UL 94-V0 |
| Colour | RAL 7035 |
| Connection cables (AWG) | AWG 12 |
| Rated operating voltage | 690 V, 3~ |
| Rated current max. | 25 A |
| Dimensions | Width: 45 mm Height: 160 mm |
| Support rails Qty/height | 1 / 15 mm |
| Packs of | 1 pc(s). |
| Net weight | 0,29 kg |
| Gross weight | 0,329 kg |
| Copper weight (kg per piece) | 0,041 |
| Customs tariff number | 85369095 |
| ETIM 9 | EC001531 |
| ECLASS 8.0 | 27370304 |
| Product description | SV Mini-PLS component adaptor, 25 A, 690 V, 3-pole, connection cable AWG 12, WH: 45x160 mm, support rail H: 15 mm |

Approvals

| | |
|-----------|------------------------|
| Approvals | UR + C-UR (recognized) |
|-----------|------------------------|

Approvals

Explanations

Declaration of conformity

Declaration of conformity UK