


**Rittal – The System.**

Faster – better – everywhere.

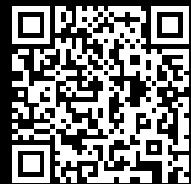

**SZ 1581.200**

**Metal gland plate**

State: 19/01/2026 (Source: [ittal.com/ie-en](https://www.ittal.com/ie-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 1581.200 - Metal gland plate with metric knockouts

Simply knock out the holes for the cable glands using a screwdriver, IP 66 when mounting in the usual position at the bottom.

## Features

Model No.	SZ 1581.200
Product description	Simply knock out the holes for the cable glands using a screwdriver.
Material	Sheet steel
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	12 x M20
Dimensions	Width: 220 mm Depth: 90 mm
To fit	Enclosure type: KX
Protection category to IEC 60 529	IP 55 if installed correctly
Type rating to UL 50E	Type 1 Type 12K
Number knockouts	12
Metric diameter	M20
Packs of	1 pc(s).
Net weight	0.23
Gross weight	0.24
PCF per pack (cradle-to-gate)	1.2 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73079100
EAN	4028177940536

# Features

---

E-Number Sweden E3465317

---

ETIM 9 EC000211

---

ETIM 8 EC000211

---

ECLASS 8.0 27142421

# Approvals

---

Approvals UL + C-UL - FTTA