 


# Rittal – The System.

Faster – better – everywhere.



## SZ 2423.000

# Spacer

State: 22/05/2026 (Source: [rittal.com/ie-en](http://rittal.com/ie-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2423.000 - Spacer for roof plate

To raise the roof for ventilation purposes, in three different heights. Not suitable for crane transportation.

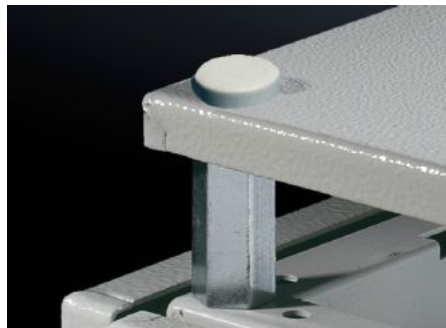

## Features

|                               |  |
|-------------------------------|--|
| Model No.                     | SZ 2423.000  |
| Product description           | To raise the roof for ventilation purposes, in three different heights.  |
| Material                      | Hexagon steel section  |
| Surface finish                | Zinc-plated  |
| Supply includes               | Assembly parts   |
| Assembly instruction          | Not suitable for crane transportation  |
| Dimensions                    | Height: 20 mm  |
| Dimensions                    | Thread: M12  |
| To fit                        | Enclosure type: VX<br>TS   |
| Packs of                      | 4 pc(s).   |
| Net weight                    | 0.216 kg   |
| Gross weight                  | 0.255 kg   |
| PCF per pack (cradle-to-gate) | 1 kg CO2 eq (Cat B)  |
| Note on PCF category          | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number         | 73269098   |

# Features

---

|                     |   |
|---------------------|---|
| ETIM 9              | EC002625                                    |
| ETIM 8              | EC002625                                    |
| ECLASS 8.0          | 27189234                                    |
| Product description | SZ Spacer, for VX, TS, roof plate, H: 20 mm |

---