


Rittal – The System.

Faster – better – everywhere.

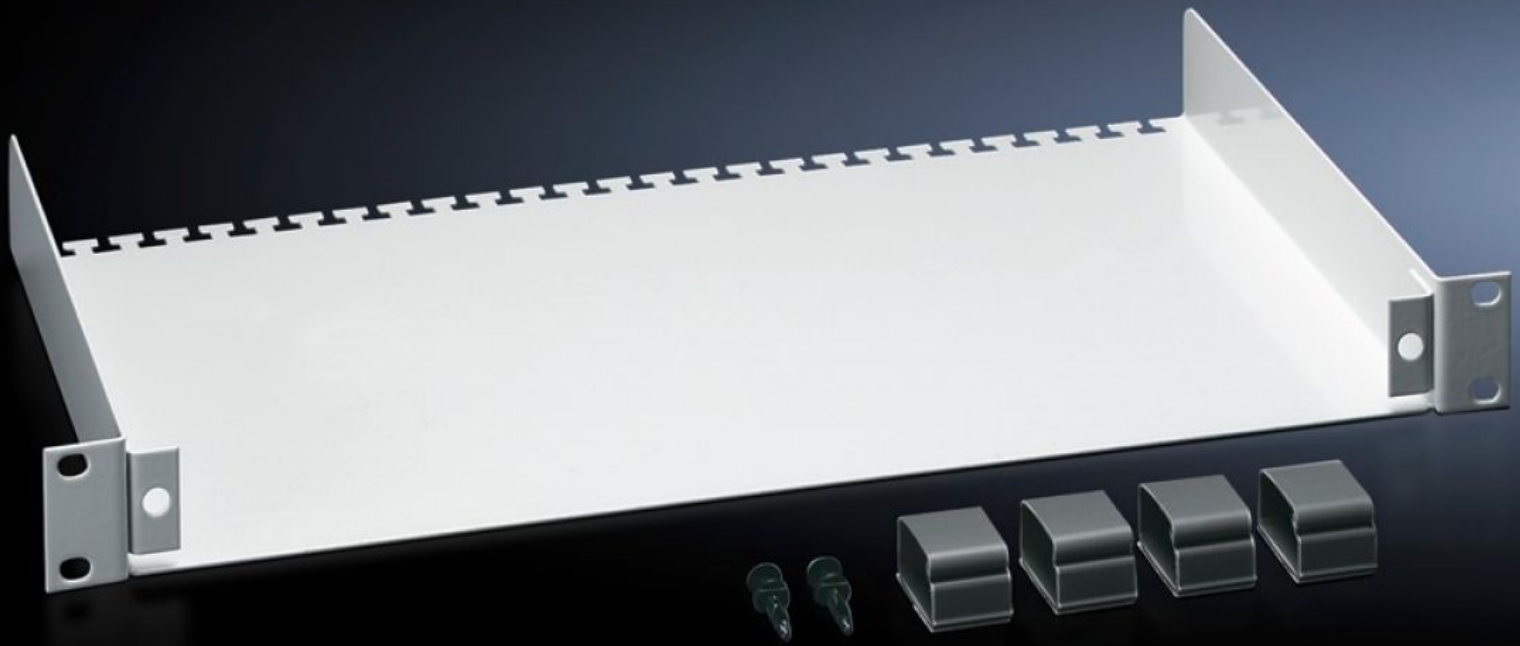

DK 7241.500

Fibre-optic breakout box, 1 U

State: 23/05/2026 (Source: rittal.com/ie-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7241.500 - Fibre-optic breakout box, 1 U

To accommodate splicing cassettes, for splice-free cabling of fibre-optic breakoutcables.

Features

| | |
|-----------------------|---|
| Model No. | DK 7241.500 |
| Product description | For splice-free cabling of fibre-optic breakout cables. Cable bundles may be clamped onto the T-heads at the rear. 4 self-adhesive cable clips are supplied loose for cable clamping and for storing excess lengths inside the box. |
| Material | Sheet steel |
| Colour | RAL 7035 |
| Supply includes | Breakout box Cable routing clips Mounting accessories for patch panel |
| Installation depth | 250 mm |
| Units | 1 U |
| Packs of | 1 pc(s). |
| Net weight | 1.5 kg |
| Gross weight | 1.684 kg |
| Customs tariff number | 94032080 |
| ETIM 9 | EC001129 |
| ECLASS 8.0 | 19170113 |
| Product description | DK Fibre-optic breakout box, 1 U, For D: 250 mm |

Tender text

Fibre-optic breakout box, 1 U, RAL 7035

Material: Sheet steel, spray finished in RAL 7035