

Rittal – The System.

Faster – better – everywhere.



VX 8619.710

Punched section with mounting flange, 14 x 39 mm

State: 22/05/2024 (Source: [rittal.com/ie-en](https://www.rittal.com/ie-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 8619.710 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.

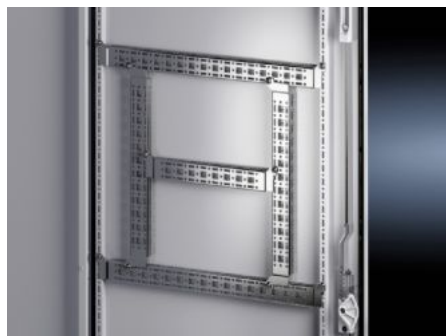

Features

Model No.	VX 8619.710
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	375 mm
To fit door width	500 mm
VX installation options	In door width 500 mm
VX SE installation options	In door width 500 mm
AX installation options	In enclosure width 400 mm and in enclosure height 500 mm, in conjunction with rail for interior installation AX In enclosure width 1000 mm, in lockable door
Installation options, AX plastic	In door width 500 mm
TP installation options	In consoles for 3-part assembly in enclosure width 600 mm, in conjunction with rail for interior installation TP, compact enclosure HD

Features

Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required
To fit	Enclosure type: VX VX SE TP AX AX plastic Suitable for width or height or depth: 500 mm
Packs of	4 pc(s).
Weight/pack	0.92 kg
Customs tariff number	73269098
EAN	4028177924635
E-Number Sweden	E3465281
ETIM 7.0	EC002625
ECLASS 8.0	27189234