


Rittal – The System.

Faster – better – everywhere.

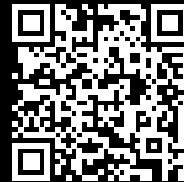

AS 4050.450 Cutting machine C8

State: 18/7/2025 (Source: rittal.com/in-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.450 - Cutting machine C8

Semi-automated machine for cutting wires to an individually adjustable size.

Features

| | |
|--------------------------|---|
| Model No. | AS 4050.450 |
| Design | With command panel |
| Product description | Semi-automated machine for cutting wires to an individually adjustable length. |
| Benefits | Easy to operate Simple insertion of the wires Simple opening of the feed rollers PC compatible |
| Technical specifications | Fine-wire strand 0.08 - 10 mm ² (AWG 28 - 8) Single-wire strand 0.08 - 2.5 mm ² (AWG 28 - 14) For wire lengths 1 - 99999 mm Feed rate 0 - 1.5 m/s Controllable pressing force of the feed rollers DC servo-drive |
| Supply includes | Cutting machine C8 Software on CD-ROM Connection cable with connector |
| Rated operating voltage | 100 V - 240 V, 1~, 50 Hz/60 Hz |
| Apparent power | 120 VA |
| Machine dimensions | Width: 380 mm Height: 470 mm Depth: 360 mm |
| Packs of | 1 pc(s). |
| Net weight | 24 |
| Gross weight | 24 |
| Customs tariff number | 84798997 |
| EAN | 4028177804845 |

Features

ECLASS 8.0

36600890