


# Rittal – The System.

Faster – better – everywhere.

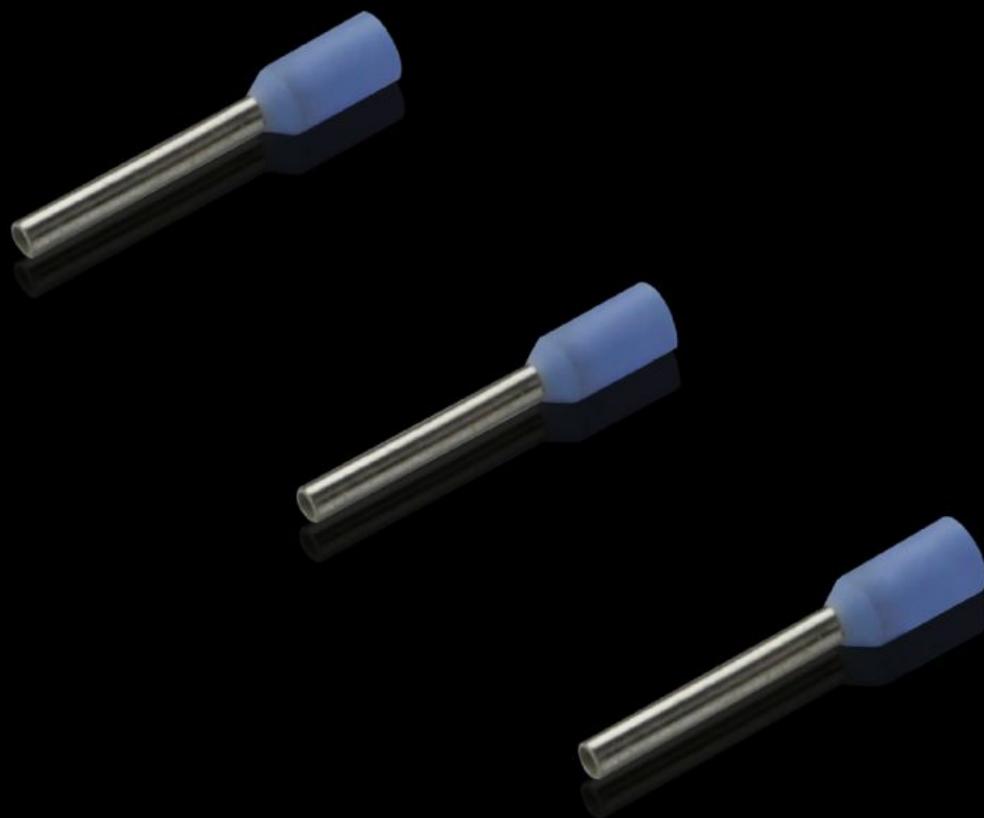

## AS 4050.754

## Wire end ferrules

State: 2/2/2026 (Source: [ittal.com/in-en](https://www.ittal.com/in-en))

# AS 4050.754 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.754
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Light blue
Length	8 mm
AWG	24
Internal diameter	1.8 mm
Rittal colour code	Yes
For cross-section	0.25 mm <sup>2</sup>
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
Delivery form	Loose
Packs of	500 pc(s).
Net weight	0.5
Gross weight	0.026
Customs tariff number	85369010
EAN	4028177815803
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0 36659290

---

## Approvals

---

Approvals UL + C-UL (listed)  
UR