


# Rittal – The System.

Faster – better – everywhere.

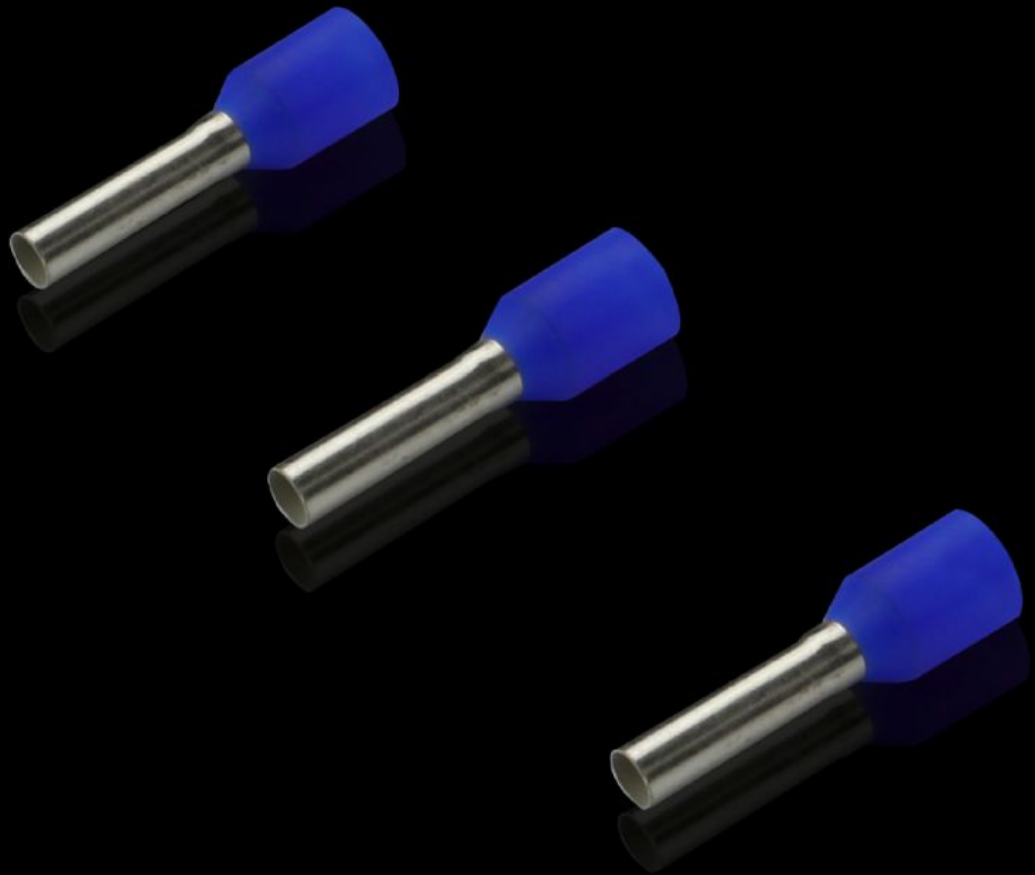

## AS 4050.779 Wire end ferrules

State: 28/5/2026 (Source: [rittal.com/in-en](http://rittal.com/in-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.779 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.779
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Blue
Length	10 mm
AWG	14
Internal diameter	4.2 mm
Rittal colour code	Yes
For cross-section	2.5 mm <sup>2</sup>
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
To fit Model No.	4051.205 4051.210
Delivery form	Loose
Packs of	500 pc(s).
Net weight	0.5 kg
Gross weight	0.083 kg
Customs tariff number	85369010
ETIM 9	EC000005
ETIM 8	EC000005

# Features

---

ECLASS 8.0	36659290
------------	----------

---

Product description	Wire end ferrules for wire processing, 2.5 mm <sup>2</sup> , AWG 14, 10 mm, blue, loose, 500 pcs.
---------------------	---

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------