


# Rittal – The System.

Faster – better – everywhere.

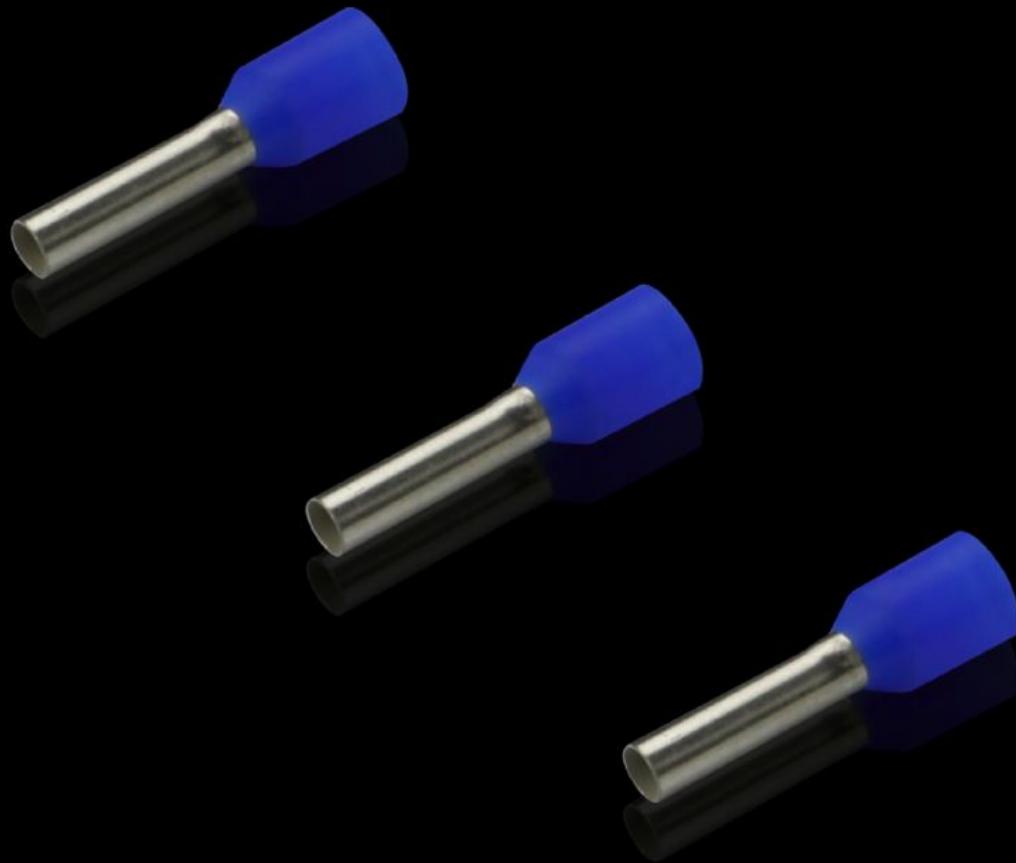

## AS 4051.525

## Wire end ferrules

State: 14/2/2026 (Source: [rittal.com/in-en](https://rittal.com/in-en))

# AS 4051.525 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4051.525
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Blue
Length	10 mm
AWG	14
Internal diameter	4.2 mm
For cross-section	2.5 mm <sup>2</sup>
DIN colour code	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
To fit Model No.	4051.205 4051.210
Delivery form	Loose (10 packs of 100)
Packs of	1,000 pc(s).
Net weight	1
Gross weight	0.176
Customs tariff number	85369010
EAN	4028177815834
ETIM 9	EC000005

# Features

---

ETIM 8 EC000005

---

ECLASS 8.0 36659290

# Approvals

---

Approvals UL + C-UL (listed)  
UR