


Rittal – The System.

Faster – better – everywhere.

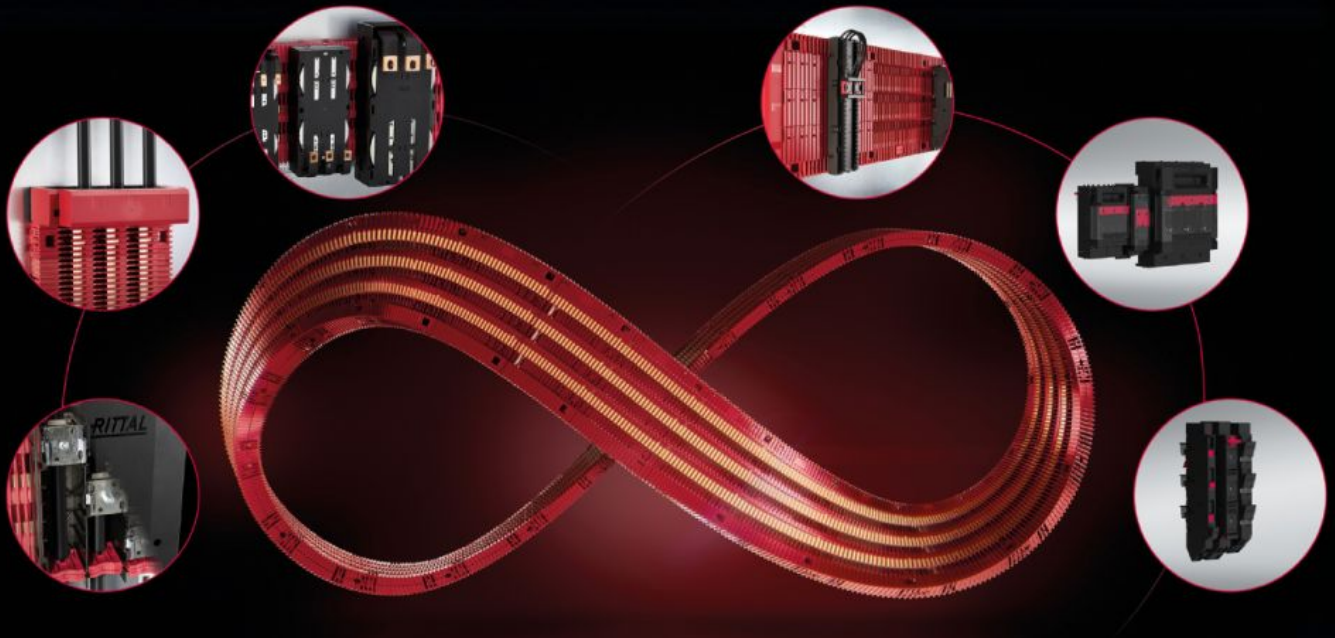

RX 9360.503 RiLineX Circuit-breaker component adaptor

상태: 2025. 8. 5 (원천: rittal.com/kr-ko)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.503 - RiLineX Circuit-breaker component adaptor

CB component adaptors for the RiLineX busbar platform in widths 81 to 140 mm. For mounting moulded-case circuit-breakers (MCCBs). Products are available in two variants: An "Easy-Fix" variant for user-friendly external mounting of switches from all standard manufacturers, and a "Universal" variant with U nuts for maximum flexibility.

특징

주문 번호	RX 9360.503
버전	Easy Fix
장점	콤팩트 회로 차단기 MCCB를 보드에 직접 장착 Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
재료	폴리아미드(PA 6) UL 94에 준하는 화재 방지 등급
색상	RAL 9005 RAL 35745
IEC 60 529에 준하는 IP 보호 등급	IP 2XB
정격 전류최대	160 A
정격 전류(UL)	125 A
정격 충격 전압 Uimp	12 kV
정격 전압으로 리던던트	690 V AC 690 V DC 600 V AC (UL)

특징

Rated insulation voltage	1,000 V
과전압 범주	4
오염 등급	3
극수	3극
케이블 출력부	상부
연결 타입, 전기의	프레임 터미널
버스바 시스템에 적합	RiLineX RiLine60
기본 진동 주파수	50...60 Hz
습도(비응축 상태)	10...90 %
버스바에 적합	15 x 5/10 20 x 5/10 30 x 5/10
작동 온도 범위	-25 °C...55 °C
저장 온도 범위	-25 °C...75 °C
치수	폭: 81 mm 높이: 252 mm 깊이: 63 mm
포장 단위	1 개

승인

승인	UL + C-UL (listed)
----	--------------------