

Rittal – The System.

Faster – better – everywhere.



RX 9360.512 RiLineX CB component adaptor

상태: 2025. 8. 20 (원천: rittal.com/kr-ko)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.512 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 250 A) for 60 mm busbar systems. The device width is 105 mm. The "Easy-Fix" concept allows adaptors and switches to be mounted independently of one another. This concept is available for all popular manufacturers. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. Version for cable outlet at the bottom.

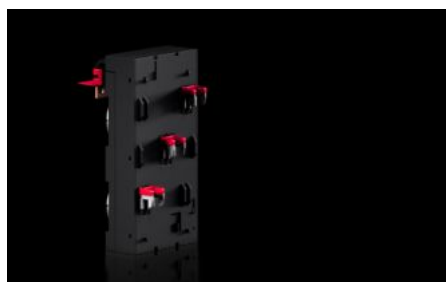

특징

주문 번호	RX 9360.512
버전	Easy Fix
장점	컴팩트 회로 차단기 MCCB를 보드에 직접 장착 Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
재료	폴리아미드(PA 6) UL 94에 준하는 화재 방지 등급
색상	RAL 9005 RAL 35745
제공 범위	3 connection space covers
IEC 60 529에 준하는 IP 보호 등급	IP 2XB
정격 전류최대	250 A

특징

정격 전류(UL)	210 A
정격 충격 전압 Uimp	12 kV
정격 전압으로 리턴던트	690 V AC 690 V DC 600 V AC (UL)
Rated insulation voltage	1,000 V
과전압 범주	4
오염 등급	3
극수	3극
케이블 출력부	하부
연결 타입, 전기의	스크류 M8

특징

제조사(모델)에 적합	ABB (S3 150, S3 225, S3, T3, T4, XT3, XT4, FE160, FE250) Chint (NM8N-250, NM1-250H, NXM-250S, NXMS-250) Eaton (LZMB2-A160, LZMB2-A250) Fuji Electric (BW160_-3P, BW250_-3) Hager (P250) Himel (HDM3-160, HDM3-250, HDM3L-160, HDM3L-250) Hyundai Electric (160, 250AF) Legrand (DPX250, DPX ³ 250) LS Electric (250AF, TS250) Mitsubishi (NF125-SGV, NF160-SGV, NF250-SV) OEZ (BD250) Rockwell (140G-J0F3-D25) Sassin (3SM8N-225, 3SM8L-225) Schneider (EZC250H, NS100, NS160, NS250, NSX100, NSX160, NSX250, GV5) Schrack (MC2) Siemens (3VA20, 3VA21, 3VA22, 3VT2, 3RV1063, 3RV1363, 3RV1364, VL160/3VL2) Terasaki (S160, S250, H250)
버스바 시스템에 적합	RiLineX RiLine60
기본 진동 주파수	50...60 Hz
습도(비응축 상태)	10...90 %
버스바에 적합	15 x 5/10 20 x 5/10 30 x 5/10
작동 온도 범위	-25 °C...55 °C
저장 온도 범위	-25 °C...75 °C

특징

치수	폭: 105 mm 높이: 252 mm 깊이: 63 mm
포장 단위	1 개
순 중량	1.7
총 무게	1.792
구리 함량(kg/개)	0.608
관세 번호	85369095
EAN	4028177997134
ETIM 9	EC001531

승인

승인	UL + C-UL (listed)
----	--------------------