


Rittal – The System.

Faster – better – everywhere.

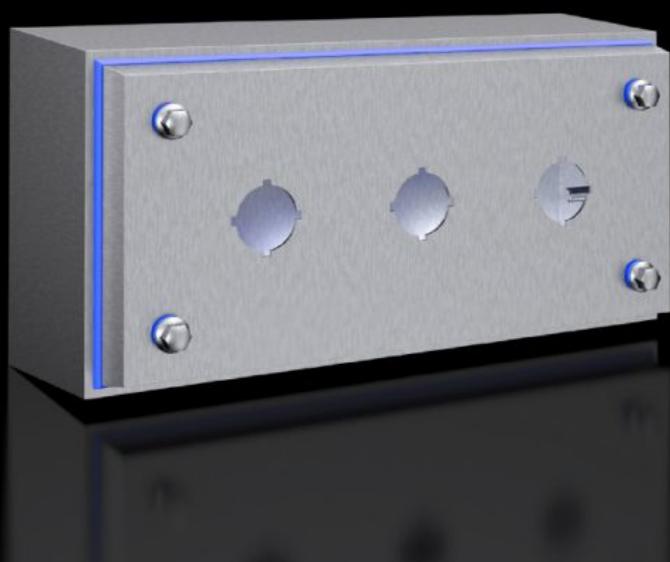

HD 1683.600

Корпуса под выключатели HD

Состояние: 03.03.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



HD 1683.600 - Корпуса под выключатели HD

Enclosure solution with three cut-outs for switches, tailored to the requirements of the food and beverage industry. All-round gap-free silicone seal between enclosure and cover. Hygiene-compliant quick-release hexagon fastener.

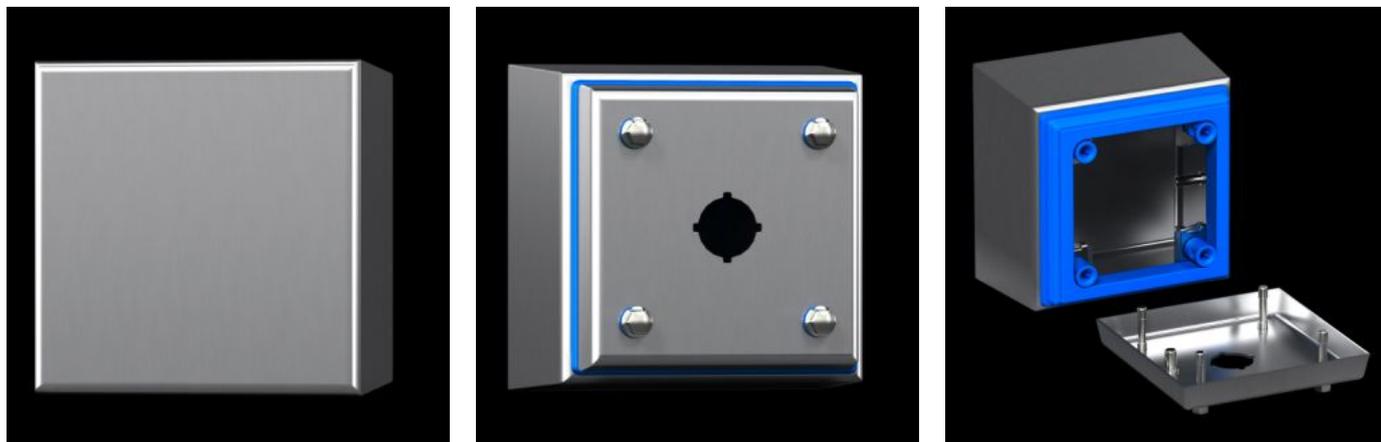

Функции

| | |
|--------------------------------|--|
| Арт. № | HD 1683.600 |
| Исполнение | Hygienic Design: корпус |
| Материал | Корпус и крышка: нержавеющая сталь 1.4301 (AISI 304) 1,5 мм Винты крышки нержавеющая сталь Уплотнение: силикон, согласно FDA 21 CFR 177.2600 |
| Поверхность | Корпус и крышка: шлифовка, зерно 400, шероховатость < 0,8 мкм Уплотнение: имеет синий цвет (RAL 5010) |
| Комплект поставки | Корпус полностью закрытый Крышка с вырезом под кнопку Уплотнение и винты запора (прилагаются) |
| Размер | Ширина спереди: 100 мм Ширина (сзади): 122 мм Высота спереди: 220 мм Высота сзади: 242 мм Глубина: 90 мм |
| Шаг раstra | 60 мм |
| Cut-outs (quantity x diameter) | 3 x 22,5 мм |

Функции

| | |
|-----------------------------------|---|
| IK-код | IK08 |
| Основной материал | Нержавеющая сталь 1.4301 (AISI 304) |
| Замок | Исполнение замка: Гигиеничный быстродействующий запор с шестигранной головкой Количество замков: 4 |
| Степень защиты IP согл. МЭК 60529 | IP 66 IP X9 |
| Protection category NEMA | NEMA 1 NEMA 3 NEMA 3X NEMA 4 NEMA 4X NEMA 12 NEMA 13 |
| Type rating согл. UL 50E | Type 1 Type 3 Type 3X Type 4 Type 4X Type 12 Type 13 |
| Упаковка | 1 шт. |
| Вес нетто | 1,42 kg |
| Gross weight | 1,62 kg |
| Код ТНВЭД | 84879090 |
| ETIM 9 | EC002713 |
| ETIM 8 | EC002713 |
| ECLASS 8.0 | 27180101 |
| Описание продукта | HD switch housing, WxHxD: 100x220x9 mm, stainless steel 1.4301, 3 switch cut-outs, Ø 22.5 mm |

Одобрения

Одобрения

UL + C-UL (listed)

Обяснения

Декларация о соответствии

Декларация о соответствии UK