


# Rittal – The System.

Faster – better – everywhere.

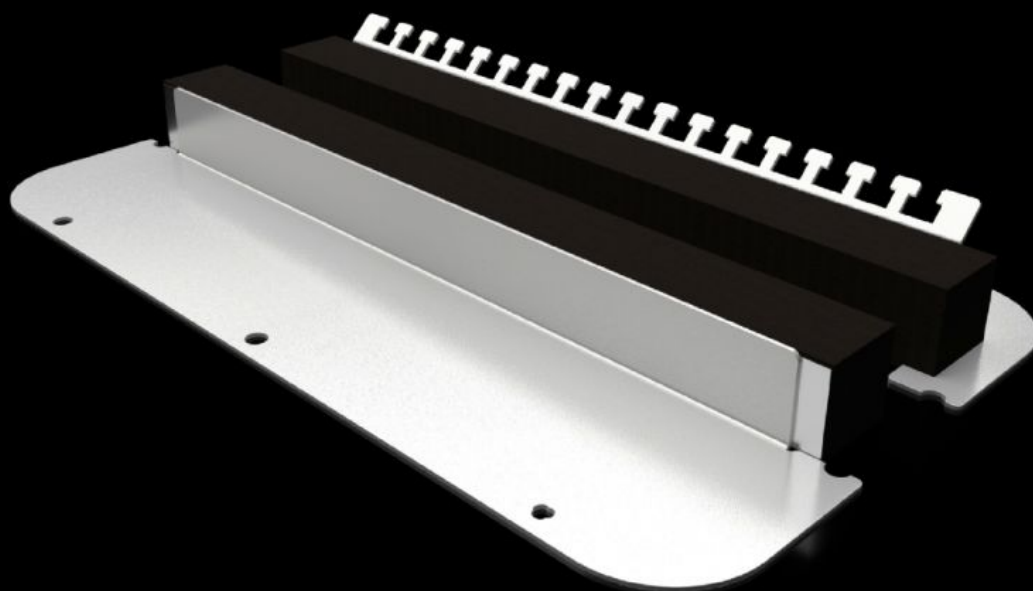

## SZ 2562.450

# Two-part gland plate with foam rubber cable clamp strip

Состояние: 23.05.2026 (Источник: [rittal.com/kz-ru](http://rittal.com/kz-ru))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2562.450 - Two-part gland plate with foam rubber cable clamp strip для AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

## Функции

Арт. №	SZ 2562.450
Исполнение	two-piece
Материал	Листовая сталь
Цвет	RAL 7035
Комплект поставки	Вкл. крепежный материал
Указание	Соответствие размеров фланш-панелей можно найти у соответствующих корпусов. When installing in enclosure width >760 mm, 2 packs are required
Размер	Ширина: 339 мм Глубина: 149 мм
Подходит для	Тип корпуса: AX
Подходит для арт. №	1031000 1038000 1045000 1077000 1094000 1380000
Фланш-панель	Размер: 2
Упаковка	1 шт.
Вес нетто	0,596 kg
Gross weight	0,796 kg
Код ТНВЭД	73269098

## Функции

---

ETIM 8	EC000211
--------	----------

---

ECLASS 8.0	27142421
------------	----------

---

Описание продукта	SZ metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD: 339x149 mm, for size 2 gland plates
-------------------	---