

Rittal – The System.

Faster – better – everywhere.



VX 5316.185

Compartment Rack VX IT

Состояние: 06.06.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX 5316.185 - Compartment Rack VX IT 4-секционная, с вентиляцией

VX IT, с вентиляцией, для системы контроля микроклимата помещения. 19" монтаж с 19" профильными шинами, с регулировкой по глубине, нагрузочная способность до 1500 кг в различных типоразмерах.

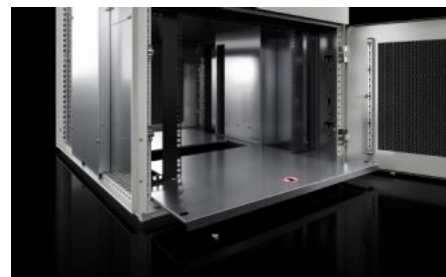

Функции

Арт. №	VX 5316.185
Преимущества	<p>Enclosure pre-configured with 482.6 mm (19") mounting angles at the front and rear of each compartment, adjustable individually and independently of each other</p> <p>Pre-configured 740 mm distance between mounting angles, individually adjustable</p> <p>Door hinges can be swapped from right to left</p> <p>Baying supported on all sides</p> <p>Air baffle plates integrated into the 19" mounting frame</p> <p>Max. door opening angle 130°, max. 115° in bayed suite</p>
Технические характеристики	Max. load capacity 250 kg per compartment
Материал	<p>Каркас шкафа: листовая сталь 1,5 мм</p> <p>Roof plate: Sheet steel, 1.5 mm</p> <p>Gland plate: Sheet steel, 1.0 mm</p> <p>Front and rear door: Sheet steel, 1.5 mm</p> <p>Mounting angles: Sheet steel, 2.5 mm</p>
General colour	RAL 7035
Цвет	<p>Рама корпуса и плоские детали: RAL 7035</p> <p>19" mounting angles, hinges and handles spray-finished in RAL 9005</p>

Функции

Комплект поставки	<p>VX IT compartment rack, with four independent installation compartments</p> <p>Each compartment with 482.6 mm (19") mounting angles, front and rear, screwed to the integrated dividers on the left and right</p> <p>Gland plate divided in the centre, pre-configured across the entire rack depth</p> <p>4 sheet steel doors, vented, front and rear</p> <p>Контрольная ручка под профильный полуцилиндр 3524 E</p> <p>Including potential equalisation, prepared for the attachment of earthing straps</p> <p>Two 482.6 mm (19") mounting angles front and rear per compartment, depth-variable, front angles with all-round integrated air baffles</p> <p>8 keys</p>
Размер	<p>Ширина: 800 мм</p> <p>Высота: 2.200 мм</p> <p>Глубина: 1.200 мм</p>
Расстояние между плоскостями (в состоянии поставки)	740 мм
Number front doors	4
Number back doors	4
19" крепление	<p>4 x 11 U</p> <p>Incl. 482.6 mm (19") mounting angles front and rear per compartment, adjustable individually and independently of each other</p>
Исполнение	Compartment Rack, 4 x 11 U
Roof design	One-piece roof plate, with cable entry on both sides in the centre part of the roof
Design doors	<p>Door opening angle max. 130°</p> <p>Incl. 2-point locking rod</p>
Rear door design	4-секционная, с вентиляцией
Front door design	4-секционная, с вентиляцией
Mounting angle design	19" mounting angles in the VX IT Compartment Rack
Base design	Base frame with pull-out, two-part solid gland plate pre-assembled

Функции

Исполнение 19" плоскости (плоскостей)	19" плоскость спереди и сзади 19" mounting level with universal mounting angles front and rear, depth-variable, 12.5 mm pitch pattern, screwed to the divider panels on the left and right, with integrated air baffle plates Air baffle plate with integral, vertical 1 U 482.6 mm (19") mounting cut-out on the right and left of each compartment, as additional interior installation space or for cable routing.
Mounting angles position	19" плоскость спереди и сзади
Указание	В зависимости от типа и места установки угол открытия двери может отличаться для конкретного случая
Основной материал	Листовая сталь
Упаковка	1 шт.
Вес нетто	235 kg
Gross weight	250 kg
Код ТНВЭД	94032080
ETIM 9	EC002499
ECLASS 8.0	27180207
Описание продукта	VX IT Compartment Rack, vented, 4 compartments, 19" mounting angles front and rear, 4 x 11 U, WHD: 800x2200x1200 mm, enclosure frame and panels: RAL 7035, interior components: RAL 9005

Одобрения

Сертификаты	Поверхность
Объяснения	Декларация производителя Декларация о соответствии