


Rittal – The System.

Faster – better – everywhere.

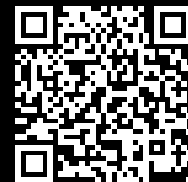

RX 9360.500

RiLineX CB component adaptor

Состояние: 18.06.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.500 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Easy-Fix" concept allows adaptors and switches to be mounted independently of one another. This concept is available for all popular manufacturers. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. Version for cable outlet at the bottom.



Функции

Арт. №	RX 9360.500
Исполнение	Easy Fix
Преимущества	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Комплект поставки	3 connection space covers
Степень защиты IP согл. МЭК 60 529	IP 2XB

Функции

Номинальное импульсное напряжение U _{imp}	8 кВ
Rated voltage	690 V AC 600 V AC (UL)
Номинальное напряжение изоляции U _i	1 000 В
Rated impulse withstand current	80 кА
Степень загрязнения	3
Количество полюсов	3-пол.
Отвод проводов	снизу
Тип подключения (электрического)	Рамная клемма
Подходит для производителя (тип)	ABB (A1, S2, T1, T2, XT1, XT2, FD63/FD160) BTicino (M1 160) Chint (NM8N-125, NM1-63H, NM1-125H, NXM-63S, NXM-125S, NXM-160S, NXMS-160) Eaton (NZM1) Fuji Electric (BW125JAG-3P) Hager (P160) Himel (HDM3-100F/N, HDM3L-125) Hyundai Electric (100AF, 125AF, 125D, 160D AF) Legrand (DPX 160, DPX 250 ER, DPX ³ 160) LS Electric (100AF, 125AF, TE100, TD100, TE160, TD160) Mitsubishi (NF63-SV, NF125-SV) OEZ (BC160) Rockwell (140G-C2C3-D10, 140G-C2C3-D12, 140-C2E3-D16, 140G-H0F3-D10, 140G-H0F3-D12, 140G-H0F3-D16) Sassin (3SM8L-100) Schneider (NSC100N, NSXm50, NSXm100, NSXm160, NSXm250, NSE100) Schrack (MC1) Siemens (3VA10, 3VA11) Terasaki (E125, S125)
Подходит для шинной системы	RiLineX RiLine60
Fundamental frequency	50...60 Гц

Функции

Влажность воздуха (без конденсата)	10...90 %
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Диапазон рабочих температур	-25 °C...55 °C
Диапазон температур хранения	-25 °C...75 °C
Размер	Ширина: 82 мм Высота: 252 мм Глубина: 63 мм
Упаковка	1 шт.
Вес нетто	1,364 kg
Gross weight	1,367 kg
Доля меди (кг / штук)	0,375
PCF per pack (cradle-to-gate)	13,28
Код ТНВЭД	85369095
ETIM 9	EC001531
Описание продукта	RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Easy-Fix" concept allows adaptors and switches to be mounted independently of one another. This concept is available for all popular manufacturers. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. Version for cable outlet at the bottom.

Одобрения

Одобрения	UL + C-UL (listed)
Объяснения	Декларация о соответствии PCF-declaration