
 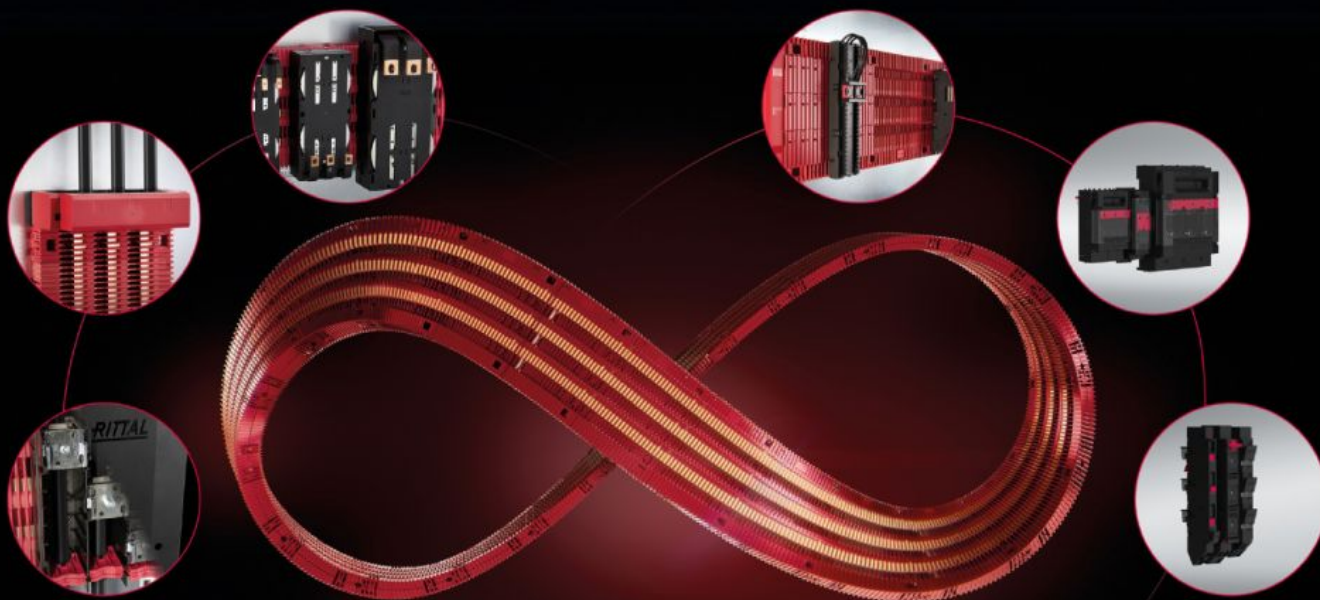


# Rittal – The System.

Faster – better – everywhere.



## RX 9360.503

# RiLineX Circuit-breaker component adaptor

Состояние: 02.08.2025 (Источник: [rittal.com/kz-ru](http://rittal.com/kz-ru))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.503 - RiLineX Circuit-breaker component adaptor

CB component adaptors for the RiLineX busbar platform in widths 81 to 140 mm. For mounting moulded-case circuit-breakers (MCCBs). Products are available in two variants: An "Easy-Fix" variant for user-friendly external mounting of switches from all standard manufacturers, and a "Universal" variant with U nuts for maximum flexibility.

## Функции

Арт. №	RX 9360.503
Исполнение	Easy Fix
Преимущества	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Степень защиты IP согл. МЭК 60 529	IP 2XB
Номинальный ток макс.	160 A
Номинальный ток (UL)	125 A
Номинальное импульсное напряжение U <sub>imp</sub>	12 кВ
Rated voltage	690 V AC 690 V DC 600 V AC (UL)
Rated insulation voltage	1 000 В
Категория перенапряжения	4
Степень загрязнения	3

## Функции

Количество полюсов	3-пол.
Отвод проводов	сверху
Тип подключения (электрического)	Рамная клемма
Подходит для шинной системы	RiLineX RiLine60
Fundamental frequency	50...60 Гц
Влажность воздуха (без конденсата)	10...90 %
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Диапазон рабочих температур	-25 °C...55 °C
Диапазон температур хранения	-25 °C...75 °C
Размер	Ширина: 81 мм Высота: 252 мм Глубина: 63 мм
Упаковка	1 шт.

## Одобрения

Одобрения	UL + C-UL (listed)
-----------	--------------------