 


# Rittal – The System.

Faster – better – everywhere.



## RX 9360.535

## RiLineX CB component adaptor

Состояние: 08.07.2026 (Источник: [rittal.com/kz-ru](http://rittal.com/kz-ru))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.535 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 630 A) for 60 mm busbar systems. The device width is 145 mm. The "Easy-Fix" concept allows adaptors and switches to be mounted independently of one another. This concept is available for all popular manufacturers. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. The cable outlet is easily converted to the top or bottom to suit individual requirements.

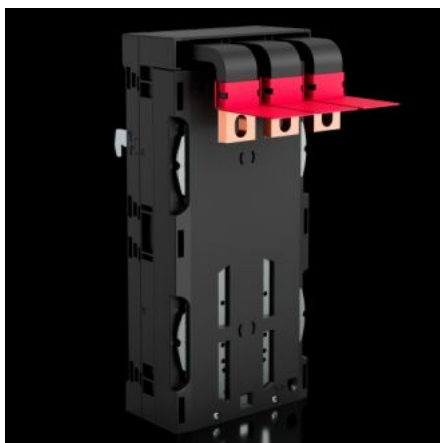

## Функции

Арт. №	RX 9360.535
Исполнение	Easy Fix
Преимущества	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Комплект поставки	3 terminal covers
Степень защиты IP согл. МЭК 60 529	IP 2XB

## Функции

Номинальное импульсное напряжение $U_{imp}$	8 кВ
Rated voltage	690 V AC 600 V AC (UL)
Номинальное напряжение изоляции $U_i$	1 000 В
Степень загрязнения	3
Количество полюсов	3-пол.
Отвод проводов	сверху/снизу
Тип подключения (электрического)	Винт M10
Сечение	29 мм <sup>2</sup> 6 мм <sup>2</sup>
Подходит для производителя (тип)	Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor.
Подходит для шинной системы	RiLineX RiLine60
Fundamental frequency	50...60 Гц
Влажность воздуха (без конденсата)	10...90 %
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Диапазон рабочих температур	-25 °C...55 °C
Диапазон температур хранения	-25 °C...75 °C
Размер	Ширина: 145 мм Высота: 325,8 мм Глубина: 76,4 мм
Fire load	22,239 MJ/m <sup>2</sup>
Упаковка	1 шт.
Вес нетто	5 kg

## Функции

Gross weight	5,206 kg
Доля меди (кг / штук)	2,64
PCF per pack (cradle-to-gate)	30,05
Код ТНВЭД	85369095
ETIM 9	EC001531
Описание продукта	RiLineX CB component adaptor (3-pole, max. 630 A) for 60 mm busbar systems. The device width is 140 mm. The "Easy-Fix" concept allows adaptors and switches to be mounted independently of one another. This concept is available for all popular manufacturers. The adaptor features tool-free snap-on mounting. The cable outlet is easily converted to the top or bottom to suit individual requirements.

## Одобрения

Одобрения	UL + C-UL (listed)
Объяснения	Декларация о соответствии PCF-declaration