


Rittal – The System.

Faster – better – everywhere.

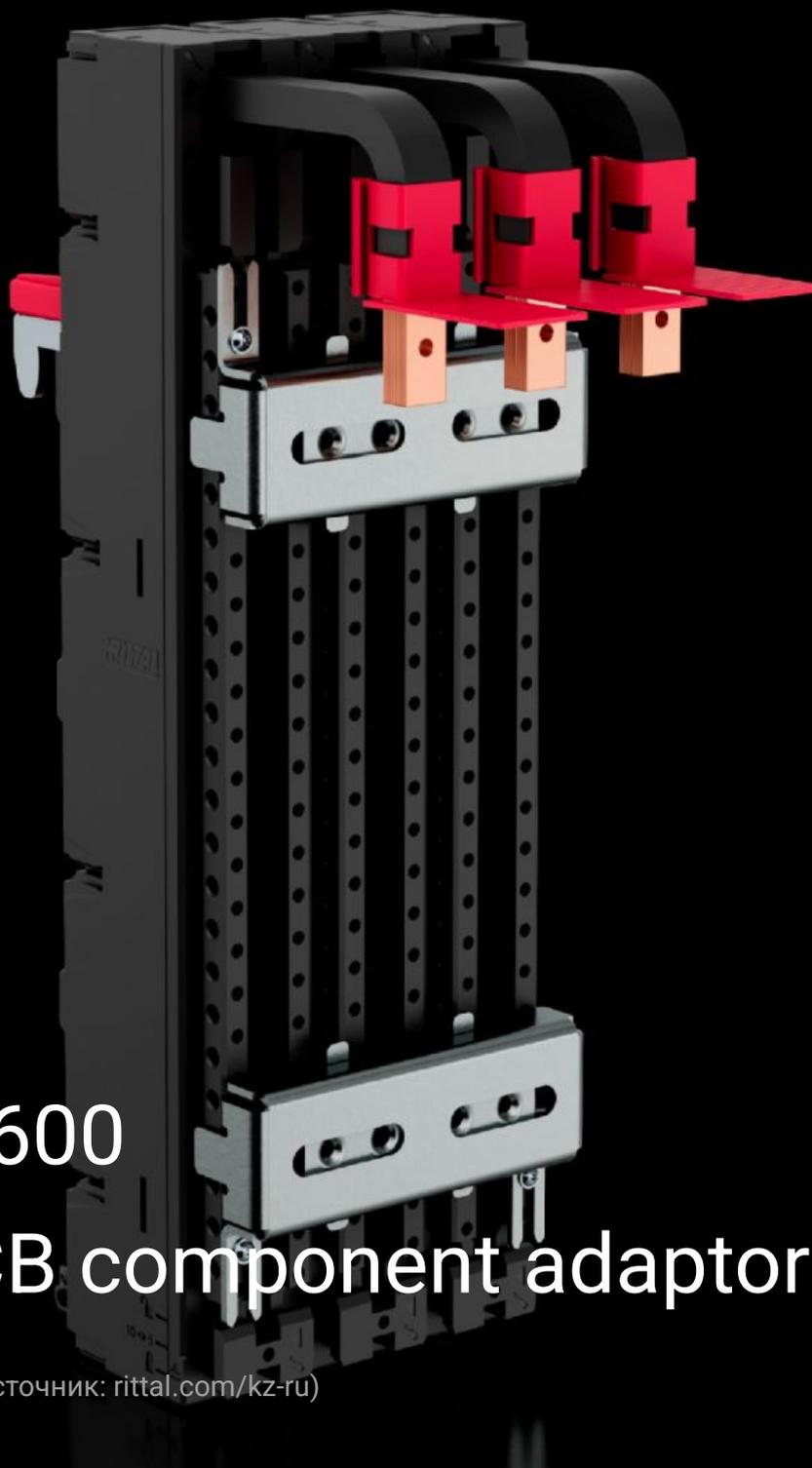

RX 9360.600

RiLineX CB component adaptor

Состояние: 10.06.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.600 - RiLineX CB component adaptor

RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting with semi-automatic adjustment of the bar thickness between 5 and 10 mm. Version for cable outlet at the bottom.

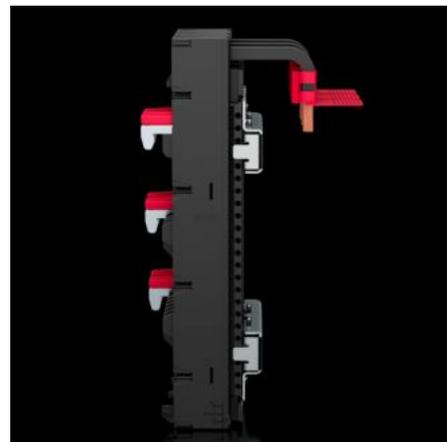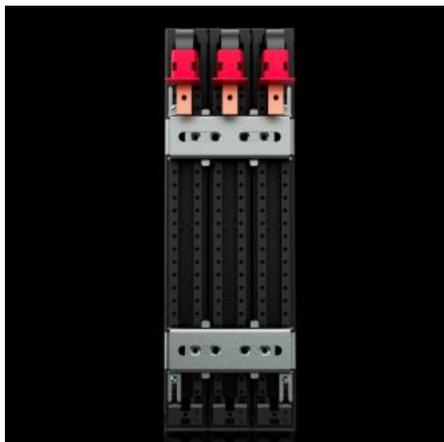

Функции

Арт. №	RX 9360.600
Исполнение	universal
Преимущества	Direct mounting of moulded-case circuit-breakers (MCCBs) on the board Snap-on mounting up to 250 A and simple adjustment to busbar thickness 5/10 mm Fast, simple pre-assembly of standard market switch types outside of the enclosure
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Комплект поставки	3 connection space covers
Степень защиты IP согл. МЭК 60 529	IP 2XB
Номинальное импульсное напряжение Uimp	8 кВ

Функции

Rated voltage	690 V AC 600 V AC (UL)
Номинальное напряжение изоляции U_i	1 000 В
Степень загрязнения	3
Количество полюсов	3-пол.
Отвод проводов	снизу
Сечение	9 мм ² 6 мм ²
Подходит для производителя (тип)	Our selection aid, available in the Downloads section, helps you to easily find a matching component adaptor.
Подходит для шинной системы	RiLineX RiLine60
Fundamental frequency	50...60 Гц
Влажность воздуха (без конденсата)	10...90 %
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Диапазон рабочих температур	-25 °C...55 °C
Диапазон температур хранения	-25 °C...75 °C
Размер	Ширина: 81,9 мм Высота: 251,4 мм Глубина: 50,8 мм
Упаковка	1 шт.
Вес нетто	0,92 kg
Gross weight	1,22 kg
Доля меди (кг / штук)	0,375
PCF per pack (cradle-to-gate)	12,73
Код ТНВЭД	85369095

Функции

ETIM 9	EC001531
Описание продукта	RiLineX CB component adaptor (3-pole, max. 160 A) for 60 mm busbar systems. The device width is 81 mm. The "Universal" variant with U nuts offers maximum flexibility for switch mounting. The adaptor features tool-free snap-on mounting. Version for cable outlet at the bottom.

Одобрения

Одобрения	UL + C-UL (listed)
Объяснения	Декларация о соответствии PCF-declaration