

# Rittal – The System.

Faster – better – everywhere.



## RX 9360.730

## RiLineX component adaptor

Состояние: 15.05.2026 (Источник: [rittal.com/kz-ru](http://rittal.com/kz-ru))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# RX 9360.730 - RiLineX component adaptor

RiLineX component adaptor (32 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

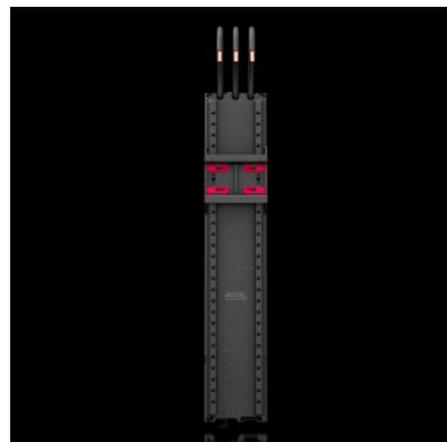

## Функции

|                          |   |
|--------------------------|---|
| Арт. №                   | RX 9360.730   |
| Исполнение               | с кабелем подключения   |
| Преимущества             | For mounting equipment for top hat rail installation, e.g. motor starter<br>Pre-assembled connection cable<br>Simple clip locking for support rails<br>Optional anti-slip guard<br>Snap-on mounting and simple adjustment for busbar thickness (5/10 mm)<br>Простой монтаж<br>Coordinated accessories reduce the number of different items required |
| Материал                 | Полиамид (PA 6)<br>Негорючесть согласно UL 94   |
| Цвет                     | RAL 9005<br>RAL 35745   |
| Кабели подключения (AWG) | AWG 10  |
| Номинальный ток (макс.)  | 40 A  |

## Функции

|  |   |
|--|---|
| Rated current of round conductor                   | 40 A  |
| Rated current of round conductor (UL)              | 40 A  |
| Отвод проводов                                     | снизу   |
| Для шинных систем с межцентровым расстоянием       | 60 mm   |
| Длина кабеля подключения                           | 160 мм  |
| Количество полюсов                                 | 3-пол.  |
| Подходит для шинной системы                        | RiLineX<br>RiLine60                                   |
| Размер   | Ширина: 45 мм<br>Высота: 239,4 мм<br>Глубина: 36,2 мм |
| Количество/высота несущих шин                      | 1 / 10 мм   |
| Подходит для шин                                   | 15 x 5/10<br>20 x 5/10<br>30 x 5/10                   |
| Rated voltage                                      | 690 V AC<br>600 V AC (UL)<br>600 V DC (UL)            |
| Степень загрязнения                                | 3   |
| Стандарты  | МЭК 60 297-1/-2<br>UL 508                             |
| Номинальное импульсное напряжение U <sub>imp</sub> | 8 кВ  |
| Номинальное напряжение изоляции U <sub>i</sub>     | 1 000 В   |
| Степень защиты IP согл. МЭК 60 529                 | IP 2XB  |
| Maximum operating air humidity                     | 90 %  |
| Диапазон рабочих температур                        | -5 °C...55 °C   |

## Функции

|                                    |  |
|------------------------------------|--|
| Диапазон температур хранения       | -25 °C...75 °C   |
| Влажность воздуха (без конденсата) | 10...90 %  |
| Упаковка                           | 4 шт.  |
| Вес нетто                          | 1,42 kg  |
| Gross weight                       | 1,45 kg  |
| Доля меди (кг / штук)              | 0,088  |
| Код ТНВЭД                          | 85369095   |
| ETIM 9                             | EC001531   |
| Описание продукта                  | RiLineX component adaptor (32 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment. |

## Одобрения

|            |  |
|------------|--|
| Одобрения  | UL + C-UL (listed)                           |
| Объяснения | Декларация о соответствии<br>PCF-declaration |