

Rittal – The System.

Faster – better – everywhere.



RX 9360.730

RiLineX component adaptor

Состояние: 07.07.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.730 - RiLineX component adaptor

RiLineX component adaptor (40 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

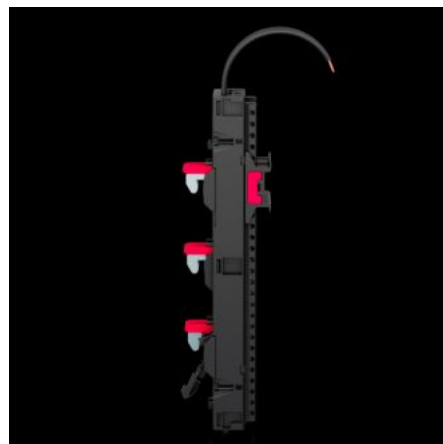

Функции

Арт. №	RX 9360.730
Исполнение	с кабелем подключения
Преимущества	For mounting equipment for top hat rail installation, e.g. motor starter Pre-assembled connection cable Simple clip locking for support rails Optional anti-slip guard Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) Простой монтаж Coordinated accessories reduce the number of different items required
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Кабели подключения (AWG)	AWG 10
Номинальный ток (макс.)	40 A

Функции

Rated current of round conductor	40 A
Rated current of round conductor (UL)	40 A
Отвод проводов	снизу
Для шинных систем с межцентровым расстоянием	60 mm
Длина кабеля подключения	160 мм
Количество полюсов	3-пол.
Подходит для шинной системы	RiLineX RiLine60
Размер	Ширина: 45 мм Высота: 239,4 мм Глубина: 36,2 мм
Количество/высота несущих шин	1 / 10 мм
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Rated voltage	690 V AC 600 V AC (UL) 600 V DC (UL)
Степень загрязнения	3
Стандарты	МЭК 60 297-1/-2 UL 508
Номинальное импульсное напряжение U _{imp}	8 кВ
Номинальное напряжение изоляции U _i	1 000 В
Степень защиты IP согл. МЭК 60 529	IP 2XB
Maximum operating air humidity	90 %
Диапазон рабочих температур	-5 °C...55 °C

Функции

Диапазон температур хранения	-25 °C...75 °C
Влажность воздуха (без конденсата)	10...90 %
Fire load	3,419 MJ/m ²
Упаковка	4 шт.
Вес нетто	1,42 kg
Gross weight	1,45 kg
Доля меди (кг / штук)	0,088
PCF per pack (cradle-to-gate)	9,34
Код ТНВЭД	85369095
ETIM 9	EC001531
Описание продукта	RiLineX component adaptor (40 A, 3-pole, including connection cables) in width 45 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

Одобрения

Одобрения	UL + C-UL (listed)
Объяснения	Декларация о соответствии PCF-declaration