 


Rittal – The System.

Faster – better – everywhere.



RX 9360.780

RiLineX component adaptor

Состояние: 06.04.2026 (Источник: rittal.com/kz-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



RX 9360.780 - RiLineX component adaptor

RiLineX component adaptor (80 A, 3-pole, including connection cables) in width 54 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

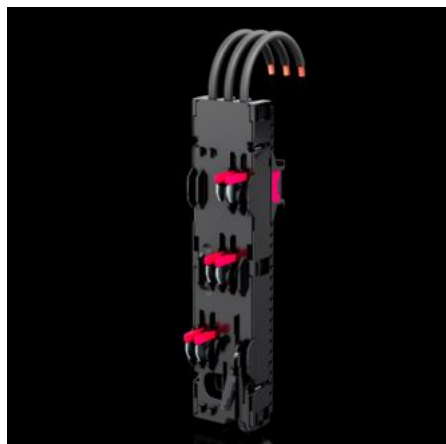

Функции

Арт. №	RX 9360.780
Исполнение	с кабелем подключения
Преимущества	For mounting equipment for top hat rail installation, e.g. motor starter Pre-assembled connection cable Simple clip locking for support rails Optional anti-slip guard Snap-on mounting and simple adjustment for busbar thickness (5/10 mm) Простой монтаж Coordinated accessories reduce the number of different items required
Материал	Полиамид (PA 6) Негорючесть согласно UL 94
Цвет	RAL 9005 RAL 35745
Кабели подключения (AWG)	AWG 4
Номинальный ток (макс.)	80 A

Функции

Rated current of round conductor	80 A
Rated current of round conductor (UL)	80 A
Electrical ratings UL (SCCR)	100 kA - 600 V, Fuse Class RK5 max. 60 A, JDDZ/7 20 kA - 600 V, circuit breaker max. 60 A, DIVQ/7 65 kA - 480 V, Combination Motor Controller max. 52 A, NKJH/7
Отвод проводов	сверху
Для шинных систем с межцентровым расстоянием	60 mm
Длина кабеля подключения	130 мм
Количество полюсов	3-пол.
Подходит для шинной системы	RiLineX RiLine60
Размер	Ширина: 54 мм Высота: 239,4 мм Глубина: 36,2 мм
Количество/высота несущих шин	1 / 10 мм
Подходит для шин	15 x 5/10 20 x 5/10 30 x 5/10
Rated voltage	690 V AC 600 V AC (UL) 600 V DC (UL)
Категория перенапряжения	4
Степень загрязнения	3
Стандарты	МЭК 60 297-1/-2 UL 508
Степень защиты IP согл. МЭК 60 529	IP 2XB
Maximum operating air humidity	90 %
Диапазон рабочих температур	-5 °C...55 °C

Функции

Диапазон температур хранения	-25 °C...75 °C
Влажность воздуха (без конденсата)	10...90 %
Упаковка	4 шт.
Вес нетто	2,12 kg
Gross weight	2,15 kg
Доля меди (кг / штук)	0,209
Код ТНВЭД	85369095
ETIM 9	EC001531
Описание продукта	RiLineX component adaptor (80 A, 3-pole, including connection cables) in width 54 mm for RiLineX and other 60 mm busbar system platforms. With fitted support rail for snap-on mounting of equipment and tool-free adjustment.

Одобрения

Одобрения	UL + C-UL (listed)
Объяснения	Декларация о соответствии PCF-declaration