


Rittal – The System.

Faster – better – everywhere.

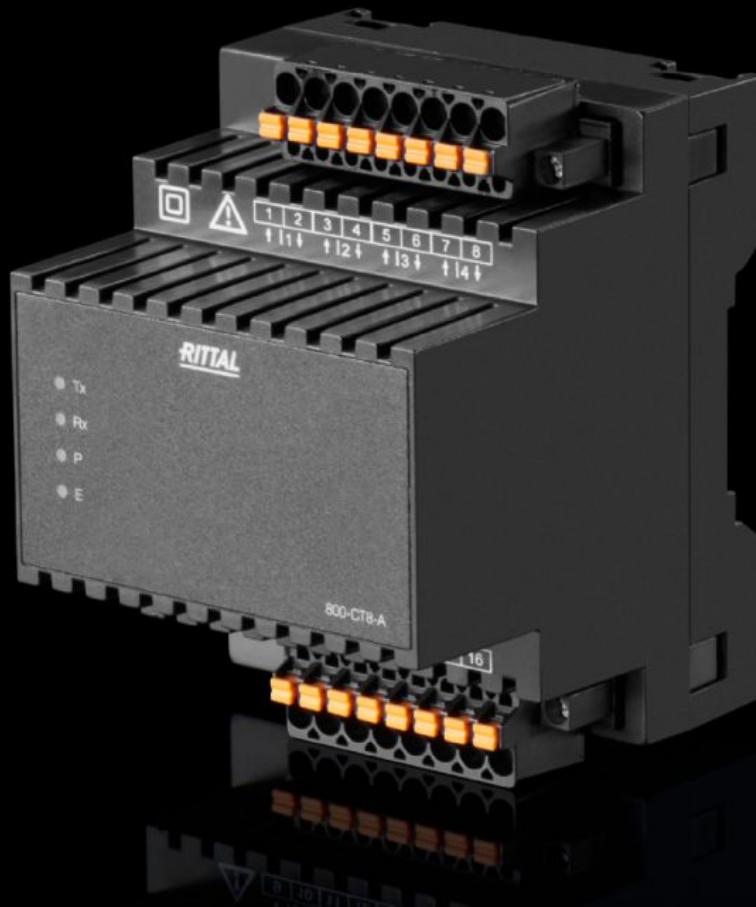

SV 9393.231

Current measurement module

Состояние: 31.01.2026 (Источник: rittal.com/kz-ru)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

SV 9393.231 - Current measurement module

To extend the modular network analyser REM 801 with 8 additional current measurement channels.

ФУНКЦИИ

Арт. №	SV 9393.231
Исполнение	REM 800-CT-8-A For secondary current transformers (1 A/5 A)
Указание к арт. №	Measurement category CAT II
Диапазон рабочих температур	-10 °C...55 °C
Диапазон температур хранения	-25 °C...70 °C
Влажность воздуха (без конденсата)	5...95 %
Степень загрязнения	2
Степень защиты IP согласно МЭК 60529	IP 20
For mounting on support rails	да
Подключение проводов, тонкопроволочных с наконечником	0,2 - 2,5 мм ²
Подключение проводов, тонкопроволочных без наконечника	0,2 мм ²
Подключение проводов, сплошных	0,2 - 2,5 мм ²
Подключение проводов, многопроволочных	0,2 - 2,5 мм ²
Nominal current for current sensors	5 A
Категория перенапряжения	300 В

Функции

Номинальное импульсное напряжение U_{imp}	2,5 кВ
Потребляемая мощность (ок.)	0,2 VA ($R_i = 5 \text{ m}\Omega$)
Диапазон измерения	0...6 A
Fundamental frequency	40...70 Гц
Harmonic	1...25
Упаковка	1 шт.
Вес нетто	0.45
Gross weight	0.503
Код ТНВЭД	85389099
EAN	4028177985025

Одобрения

Объяснения

Декларация о соответствии