


Rittal – The System.

Faster – better – everywhere.

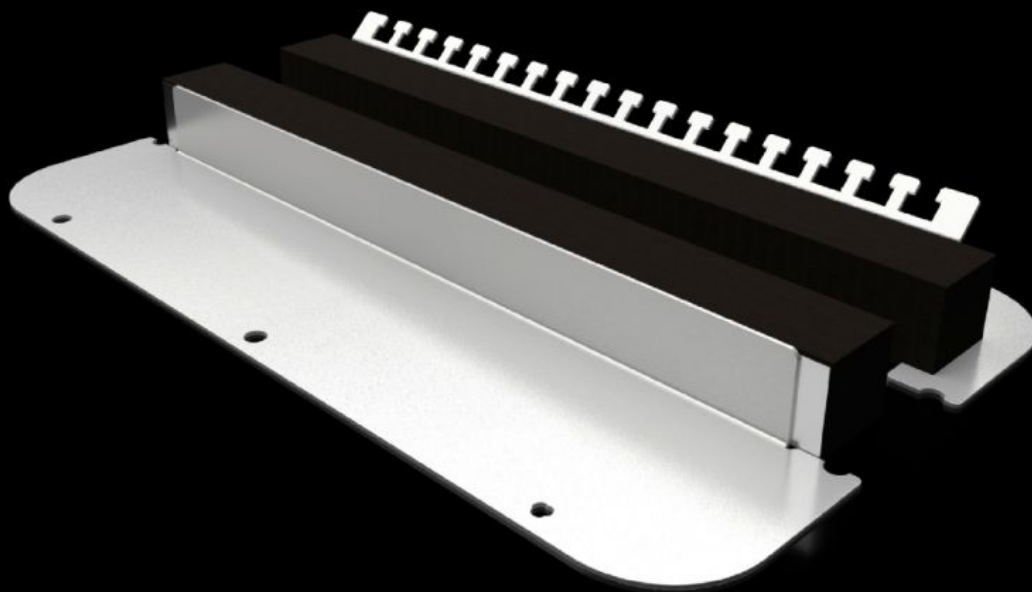

SZ 2562.450

**Two-part gland plate with foam
rubber cable clamp strip**

State: 2026.5.22 (Source: rittal.com/lt-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2562.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

Features

Model No.	SZ 2562.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required
Dimensions	Width: 339 mm Depth: 149 mm
To fit	Enclosure type: AX
To fit Model No.	1031000 1038000 1045000 1077000 1094000 1380000
Gland plate	Size: 2
Packs of	1 pc(s).
Net weight	0.596 kg
Gross weight	0.796 kg
Customs tariff number	73269098

Features

ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD: 339x149 mm, for size 2 gland plates
