

# Rittal – The System.

Faster – better – everywhere.



## SZ 2565.200

### Plastic gland plate, modular

State: 2026.2.1 (Source: [ittal.com/lt-en](https://ittal.com/lt-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2565.200 - Plastic gland plate, modular with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).

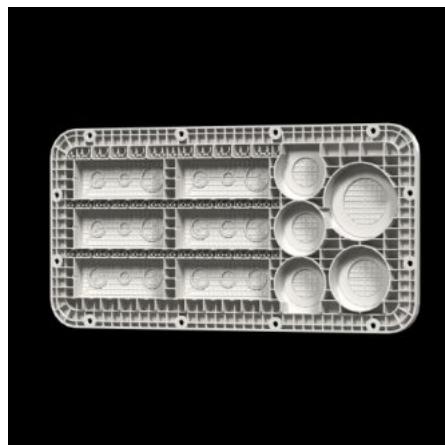

## Features

Model No.	SZ 2565.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frame allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Colour	RAL 7035
Number of rectangular cutouts information	1 rectangular cut-out can hold 10 small seal inserts
Number of rectangular cutouts	5
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	4 x M12 4 x M16 4 x M20 3 x M25 1 x M32 1 x M40

# Features

Dimensions	Width: 301 mm Depth: 221 mm
To fit	Enclosure type: AX
Gland plate	Size: 5
Operating temperature range	-40 °C...80 °C
Protection category to IEC 60 529	IP 66 if installed correctly
Type rating to UL 50E	Type 1 Type 12
Number knockouts	4 4 4 3 1 1
Metric diameter	M12 M16 M20 M25 M32 M40
Packs of	1 pc(s).
Net weight	0.4
Gross weight	0.418
Customs tariff number	39269097
EAN	4028177938434
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

# Approvals

# Approvals

---

Approvals

UL + C-UL - FTTA