
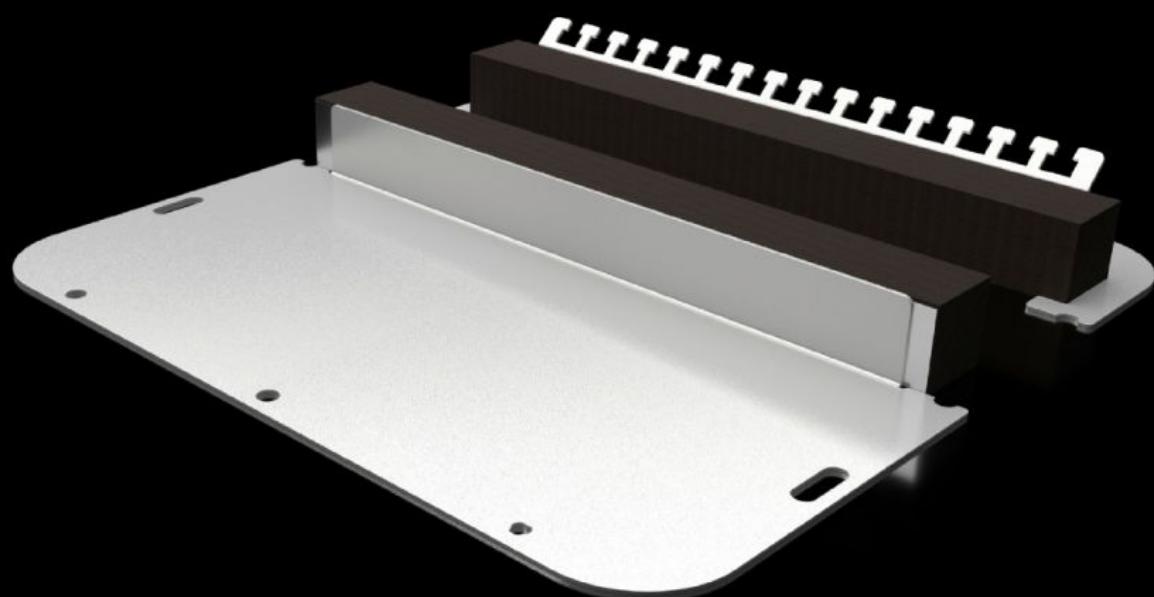


# Rittal – The System.

Faster – better – everywhere.

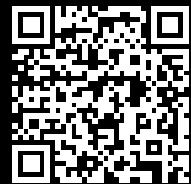

## SZ 2565.450

Two-part gland plate with foam  
rubber cable clamp strip

State: 2026.1.30 (Source: [ittal.com/lt-en](https://www.ittal.com/lt-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# SZ 2565.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

## Features

Model No.	SZ 2565.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	<p>The allocation of gland plate sizes is indicated on the relevant enclosures</p> <p>When installing in enclosure width &gt;760 mm, 2 packs are required</p>
Dimensions	<p>Width: 301 mm</p> <p>Depth: 221 mm</p>
To fit	Enclosure type: AX
To fit Model No.	<p>1037.000</p> <p>1055.000</p> <p>1073.000</p> <p>1180.000</p> <p>1280.000</p> <p>1338.000</p> <p>1181.000</p> <p>1281.000</p>
Gland plate	Size: 5
Packs of	1 pc(s).
Net weight	0.95
Gross weight	1.02

# Features

---

PCF per pack (cradle-to-gate)	3.9 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73079100
EAN	4028177973152
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

---