


# Rittal – The System.

Faster – better – everywhere.

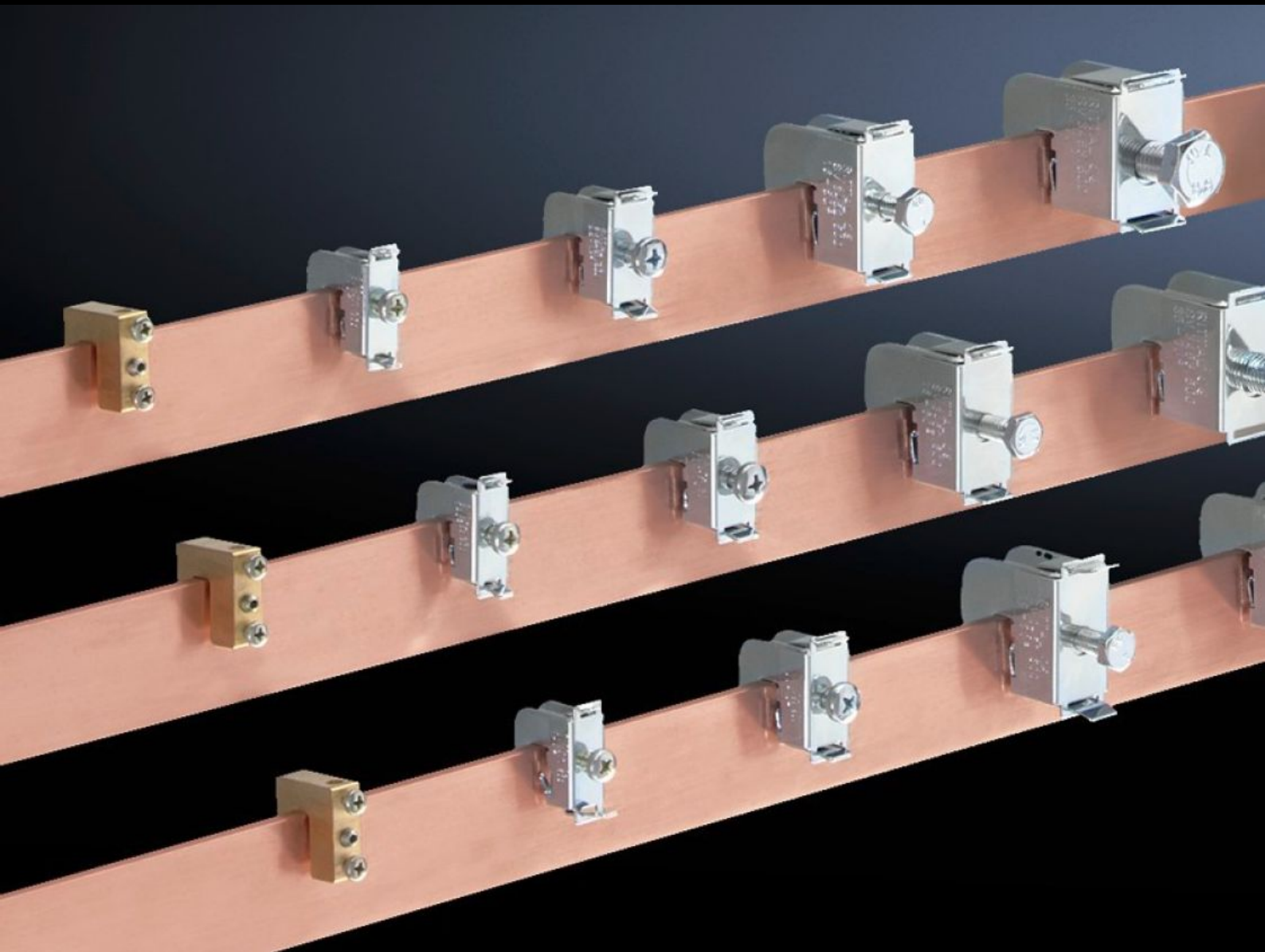

## SV 3550.000

## Conductor connection clamp

State: 2025.9.11 (Source: [rittal.com/lt-en](https://www.rittal.com/lt-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 3550.000 - Conductor connection clamp

For connecting round conductors and laminated copper bars.

## Features

|                                |  |
|--------------------------------|--|
| Model No.                      | SV 3550.000  |
| Product description            | For connecting round conductors and laminated copper bars.   |
| Material                       | Brass  |
| Note                           | Wire end ferrules should be used with fine wire conductors   |
| Connection of round conductors | 1 - 4 mm <sup>2</sup>  |
| For bar thickness              | 3 - 5 mm   |
| Packs of                       | 15 pc(s).  |
| Net weight                     | 0.315  |
| Gross weight                   | 0.358  |
| PCF per pack (cradle-to-gate)  | 1.4 kg CO2 eq (Cat B)  |
| Note on PCF category           | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared |
| Customs tariff number          | 85369010   |
| EAN                            | 4028177044159  |
| ETIM 9                         | EC000001   |
| ETIM 8                         | EC000001   |
| ECLASS 8.0                     | 27141146   |

## Approvals

|              |   |
|--------------|---|
| Explanations | Declaration of conformity<br>Declaration of conformity UK |
|--------------|---|

# Tender text

SV conductor connection clamps  
for E-CU busbars and Rittal PLS.

For bar thickness: 3 - 5 mm

Connection: for round conductors 1 - 4 mm<sup>2</sup>

Wire end ferrules should be used with fine wire  
conductors.

Tightening torque

Conductor connection clamp: 2 Nm

Material: brass