


Rittal – The System.

Faster – better – everywhere.

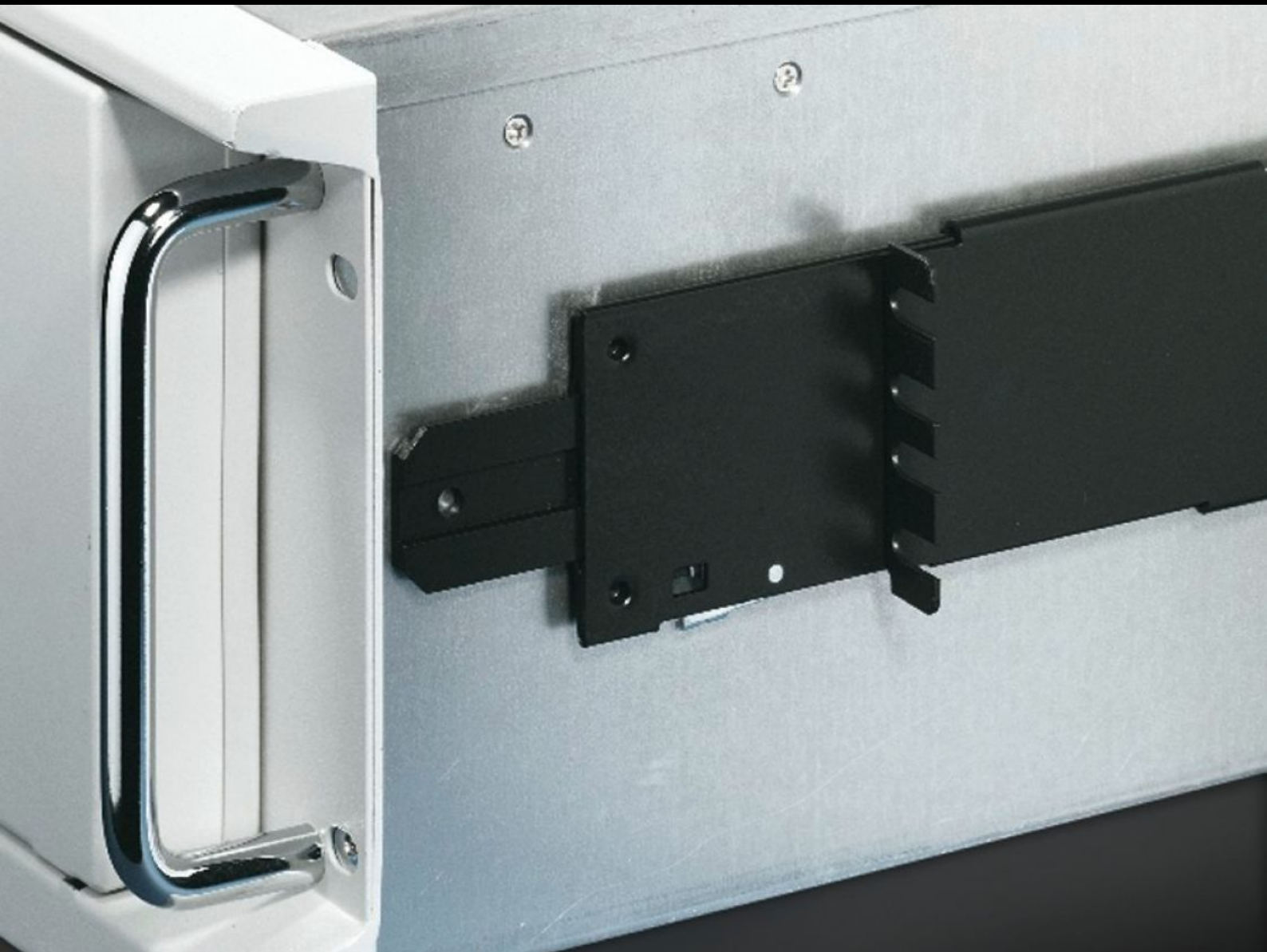

TS 3659.190

Server telescopic slides

State: 2026.3.28 (Source: [rittal.com/lt-en](https://www.rittal.com/lt-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 3659.190 - Server telescopic slides

For optimum accessibility to the servers, even when built-in.

Features

Model No.	TS 3659.190
Design	For 559.0-789.0 mm distance between levels
Product description	Facilitate optimum accessibility to the servers, even when built-in. For servers with a maximum width of 426 mm.
Material	Sheet steel
Supply includes	Telescopic slide with mounting kit Assembly parts
Extension length	596.4 mm
To fit	Enclosure type: TS: 800 mm Enclosure type: TS IT
Load capacity	30 kg
Note	Only in conjunction with L-shaped mounting angles
Packs of	2 pc(s).
Net weight	2.946 kg
Gross weight	3.146 kg
Customs tariff number	73269098
ETIM 9	EC002520
ETIM 8	EC002520
ECLASS 8.0	27189261
Product description	TS server telescopic slides, for D: 800 mm, extension piece: 596.4 mm, for TS, TS IT