


Rittal – The System.

Faster – better – everywhere.

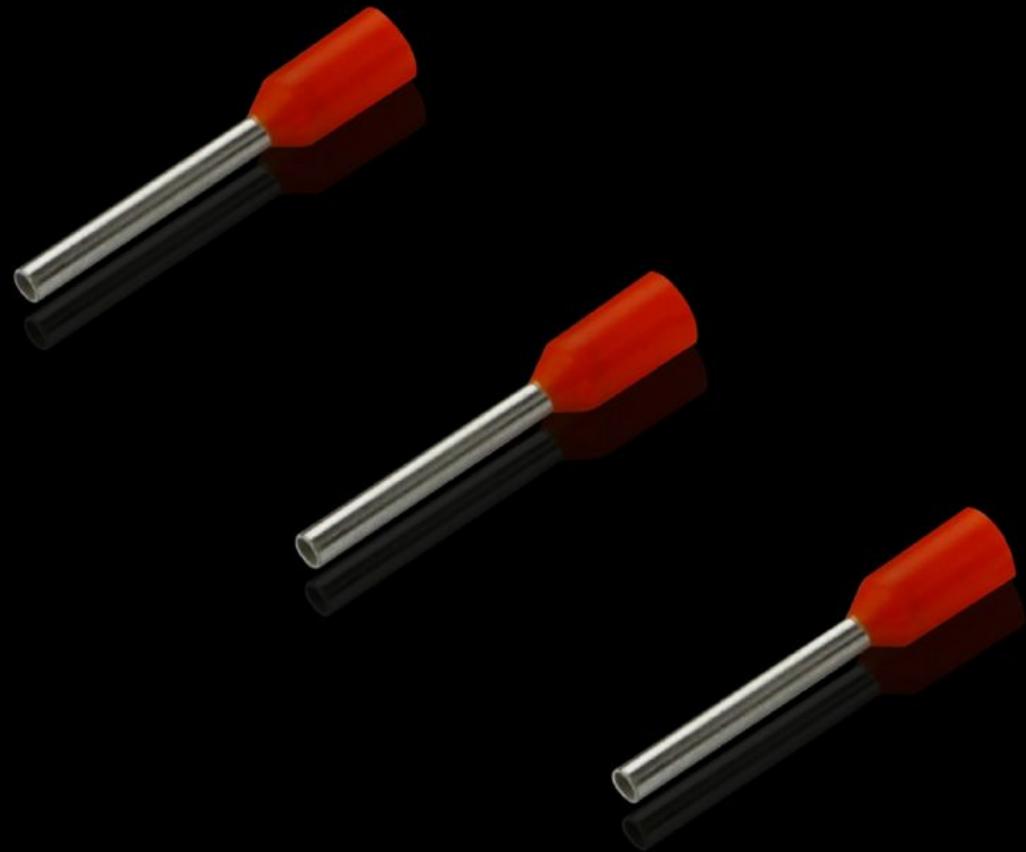

AS 4050.761

Wire end ferrules

State: 2026.2.13 (Source: rittal.com/lt-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

AS 4050.761 - Wire end ferrules loose

With plastic collar.

Features

| | |
|--------------------------|---|
| Model No. | AS 4050.761 |
| Product description | With plastic collar. |
| Technical specifications | Heat-resistant to 105 °C |
| Material | E-Cu, galvanic tin-plated Plastic collar: Polypropylene |
| Colour | Orange |
| Length | 10 mm |
| AWG | 20 |
| Internal diameter | 2.6 mm |
| Rittal colour code | Yes |
| For cross-section | 0.5 mm ² |
| Note | UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant. |
| Standards | AEH DIN 46228 |
| To fit Model No. | 4051.205 4051.210 |
| Delivery form | Loose |
| Packs of | 500 pc(s). |
| Net weight | 0.5 |
| Gross weight | 0.042 |
| Customs tariff number | 85369010 |
| EAN | 4028177815773 |
| ETIM 9 | EC000005 |

Features

ETIM 8 EC000005

ECLASS 8.0 36659290

Approvals

Approvals UL + C-UL (listed)
UR