


Rittal – The System.

Faster – better – everywhere.

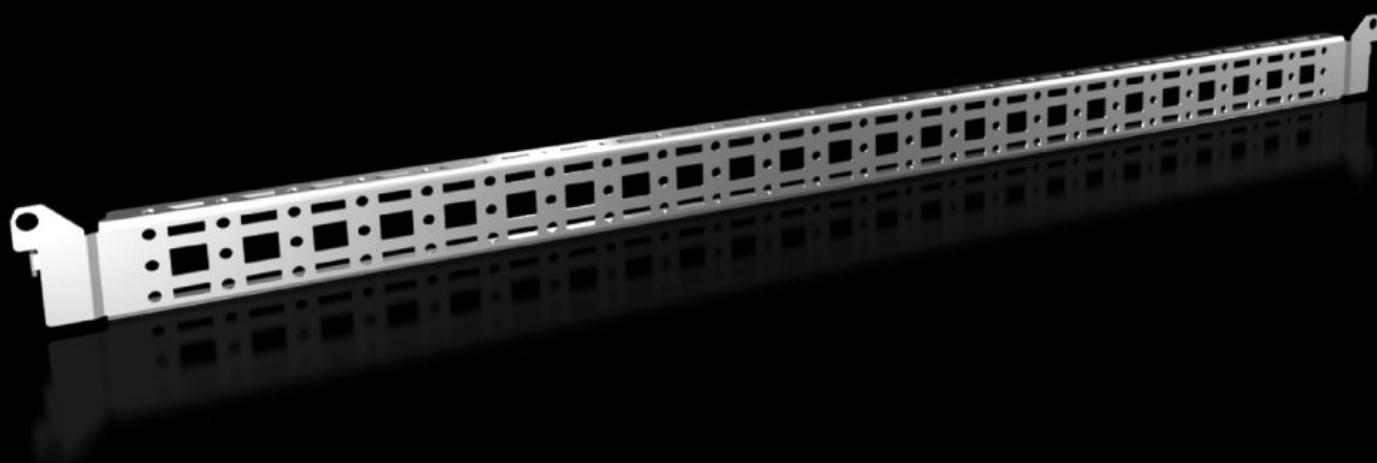

VX 8619.760

Punched section with mounting
flange, 14 x 39 mm

State: 2026.1.29 (Source: [ittal.com/lt-en](https://www.ittal.com/lt-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

VX 8619.760 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.

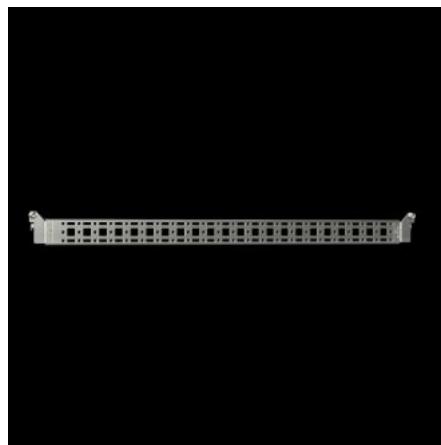

Features

Model No.	VX 8619.760
Product description	For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Distance between fixing points	575 mm
AX installation options	In enclosure width 600 mm and in enclosure height 700 mm, in conjunction with rail for interior installation AX
Assembly instruction	For installation in AX sheet steel, only in conjunction with rail for interior installation AX
Note	For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required
To fit	Enclosure type: AX Suitable for width or height or depth: 700 mm
Packs of	4 pc(s).

Features

Net weight	1.2
Gross weight	1.374
Customs tariff number	73269098
EAN	4028177926851
E-Number Sweden	E3465284
ETIM 9	EC002620
ECLASS 8.0	27189234
