


Rittal – The System.

Faster – better – everywhere.

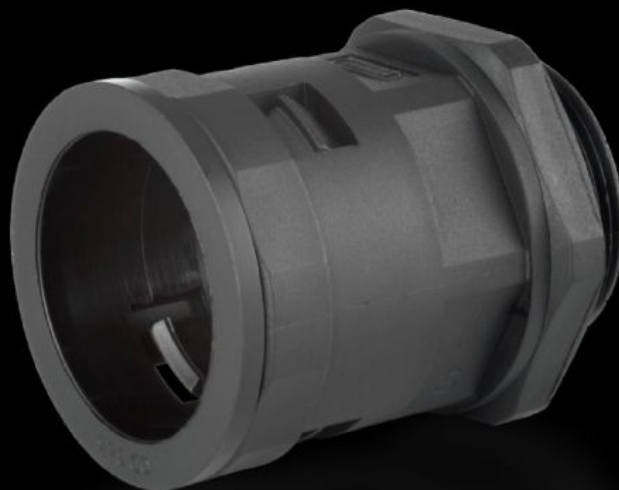

undefined 1.533.1601.50 Polyamide fitting

Staat: 2-8-2025 (Bron: rittal.com/nl-nl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



undefined 1.533.1601.50 - Polyamide fitting

Fitting van polyamide, grondstof volgens UL94, Borgmoer optioneel



Funcities

Bestelnr.	1.533.1601.50
Product omschrijving	Polyamide fitting
Voordelen	Eenvoudige montage zonder gereedschap
Materiaal	Polyamide
Kleur	RAL 9005
Afmetingen	Hoogte: 26,5 mm
Beschermklasse IP volgens IEC 60529	IP 55
Afmetingen	Schroefdraad: M16 Schroefdraadlengte: 11 mm
Bedrijfstemperatuurbereik	-30 °C...80 °C
Schroefdraadlengte	11 mm
Suitable for Polyamid hose DN	12 mm
Geschikt voor Ø	10,9 - 26 mm
Leveringseenheid	50 st.
Douanetariefnummer	39269097
EAN	4033878424179