


**Rittal – The System.**

Faster – better – everywhere.

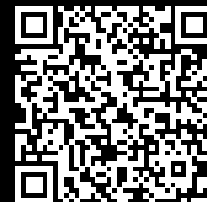

# undefined 1.542.2014.50 Polyamide fitting Duo-PA

Staat: 3-5-2026 (Bron: rittal.com/nl-nl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# undefined 1.542.2014.50 - Polyamide fitting Duo-PA

Fitting van polyamide, 2 in 1 kabelwartel en buisfitting

## Funcities

|                               |  |
|-------------------------------|--|
| Bestelnr.                     | 1.542.2014.50  |
| Product omschrijving          | Polyamide fitting voor flexibele polyamidebuis             |
| Voordelen                     | Eenvoudige montage zonder gereedschap                      |
| Materiaal                     | Polyamide<br>Dichtring: NBR/FKM<br>Afdichtingselement: NBR |
| Kleur                         | RAL 9005   |
| Afmetingen                    | Hoogte: 46 mm  |
| Kabelinvoer                   | Min. kabeldiameter: 10 mm<br>Max. kabeldiameter: 14 mm     |
| Afmetingen                    | Schroefdraad: M20<br>Schroefdraadlengte: 10 mm             |
| Bedrijfstemperatuurbereik     | -40 °C...100 °C  |
| Schroefdraadlengte            | 10 mm  |
| Suitable for Polyamid hose DN | 14 mm  |
| Geschikt voor Ø               | 29 mm  |
| Leveringseenheid              | 50 st.   |
| Douanetariefnummer            | 39269097   |