

Rittal – The System.

Faster – better – everywhere.



SV 3057.000 Railsteun

Staat: 15-5-2026 (Bron: rittal.com/nl-nl)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SV 3057.000 - Railsteun

Voor railsystemen 1250 A (100 mm), 1600 A (185 mm), 2500 A (150 mm), 3000 A (150 mm).

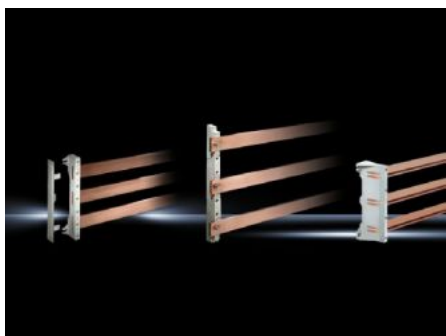

Functies

Bestelnr.	SV 3057.000
Materiaal	Glasvezelversterkt, thermoplastisch polyester (PBT) Vlamdovend volgens UL 94-V0
Kleur	RAL 7035
Aantal polen	3-polig 150 mm
Geschikt voor railkoper	60 x 10 80 x 10 100 x 10
Nominale stroom max.	3.000 A
Afmetingen	Breedte: 30 mm Hoogte: 420 mm Diepte: 170 mm
Leveringseenheid	2 st.
Nettogewicht	4,496 kg
Brutogewicht	4,695 kg
Douanetariefnummer	85469010
ETIM 9	EC001166
ETIM 8	EC001166
ECLASS 8.0	27400607

Funcities

Product omschrijving

SV Stroomrailsteun voor railkoper E-Cu 2x100x10 mm, 3000A, 3-polig, hartafstand=150 mm

Goedkeuringen

Verklaringen

Verklaring van conformiteit
Verklaring van conformiteit UK