

# Rittal – The System.

Faster – better – everywhere.



## DK 7859.090 PSM Zero-U-Space

Stat: 28.05.2026 (Kilde: [rittal.com/no-no](http://rittal.com/no-no))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7859.090 - PSM Zero-U-Space

Modulær PDU for plassbesparende integrering i Zero-U-Space mellom sidevegg og 19"-montasjenivå ved 800 mm brede IT-rack.

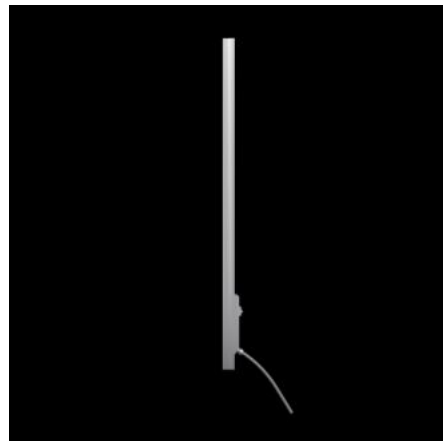

## Funksjoner

Art.nr	DK 7859.090
Produktbeskrivelse	Modulær PDU for plassbesparende integrering i Zero-U-Space mellom sidevegg og 19"-montasjenivå ved 800 mm brede IT-rack.
Materiale	Aluminiumsprofil, natur eloksert
Lengde	1 695 mm
Lengde tilkoblingskabel	3 m
Tilkoblingsmåte (elektrisk)	fast/CEE
Antall	1
Faser per innmating	1~
Merkestrøm (maks.)	32 A
Modul-pluggplasser (maks.)	5
Kapslingsgrad IP iht. IEC 60 529	IP 20
Dimensjoner	Lengde: 1.695 mm
Passer for	Kapslingstype: VX IT Høyde: ≥ 2.000 mm
Driftstemperaturområde	5 °C...45 °C

# Funksjoner

---

Luftfuktighet (ikke kondenserende)	10...90 %
Pakkeenhet	1 stk.
Nettovekt	4,9 kg
Bruttovekt	5,2 kg
Tolltariffnummer	85369001
ETIM 9	EC002762
ECLASS 8.0	27371306

---

Produktbeskrivelse	DK modular PDU, PSM busbar, modular power distribution for vertical installation, in the Zero-U-Space for 800 mm wide IT racks, 1~, 32 A, length 1695 mm, module slots: 5, infeeds: 1, connection cable length: 3 m, CEE connector, for enclosure height 2000 mm, aluminium section, natural anodised
--------------------	---

# Godkjenninger

---

Forklaringer	Samsvarserklæring
--------------	-------------------