

# Rittal – The System.

Faster – better – everywhere.



## DK 5502.370

## Gland plate, one-piece, vented

State: 13/03/2026 (Source: [rittal.com/nz-en](http://rittal.com/nz-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 5502.370 - Gland plate, one-piece, vented for TS IT

Potential equalisation is provided via assembly components and earthing points. The gland plate set is used to conceal the entire base opening.

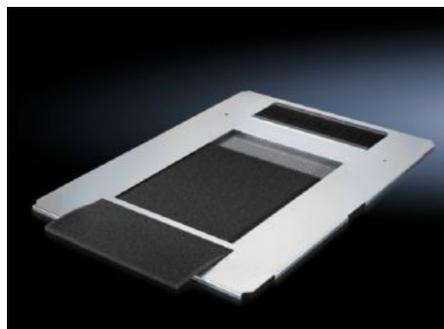

## Features

Model No.	DK 5502.370
Product description	To completely cover the open base assembly in one piece. Perforated over the entire surface. This allows cold air to flow in from the base or base/plinth area. This ensures the inflow of cold air, particularly in enclosures with rack climate control. With a brush strip at the rear for user-friendly cable entry from below across the entire enclosure width. Integral guides permit simple accommodation of a filter mat, which is also readily replaced.
Material	Sheet steel Brush strip: Plastic, UL 94-HB Filter mat: Foamed plastic
Surface finish	Zinc-plated
Supply includes	Gland plate, one-piece, vented, with cable entry at the rear Filter mat Assembly parts
To fit	Enclosure type: TS IT TX CableNet Width: 800 mm Depth: 1,200 mm
Packs of	1 pc(s).
Net weight	7.76 kg

# Features

Gross weight	9.56 kg
Customs tariff number	73269098
ETIM 9	EC002620
ECLASS 8.0	27189261
Product description	DK Gland plate, one-piece, vented, with cable entry at the rear, incl. filter mat, for TS IT, CableNet, WxD: 800x1200 mm

## Tender text

Grand plate, one-piece, vented,  
With cable entry at the rear  
For TS, TS IT, TX CableNet  
WxD: 800 x 1200 mm  
Sheet steel  
Brush strip: Plastic, UL 94-HB  
Filter mat: Foamed plastic