


# Rittal – The System.

Faster – better – everywhere.

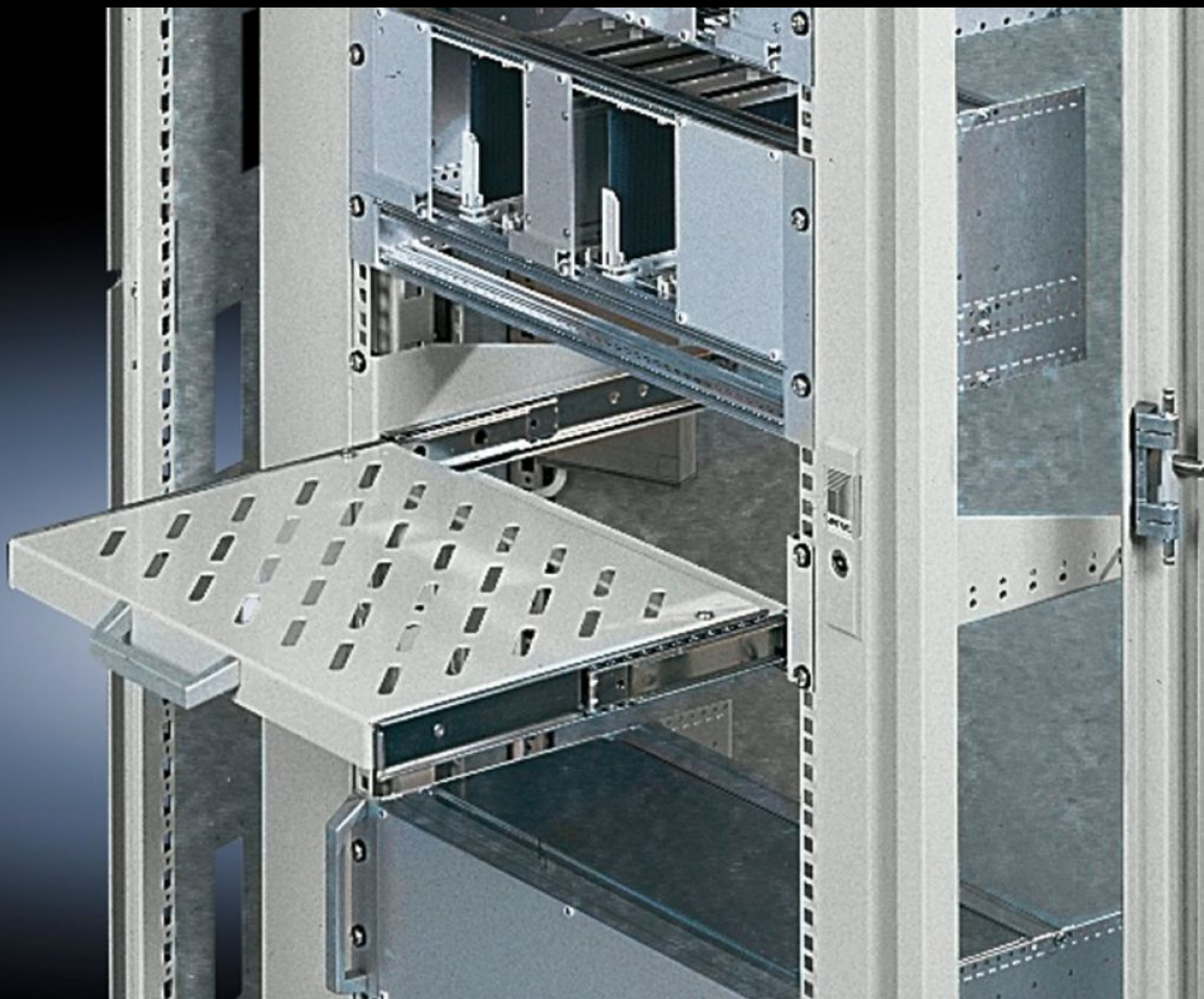

## DK 7148.035

### Component shelf 2 U

State: 17/07/2025 (Source: [rittal.com/nz-en](http://rittal.com/nz-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7148.035 - Component shelf 2 U 482.6 mm (19") system punchings

Suitable for installation in all enclosures with only one 482.6 mm (19") recess and all swing frames with flange mounting, 482.6 mm (19"), load capacity: 25 kg.

## Features

Model No.	DK 7148.035
Product description	Suitable for installation in all enclosures with only one 482.6 mm (19") recess and all swing frames with flange mounting, 482.6 mm (19").
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Dimensions	Width: 390 mm Depth: 300 mm
Packs of	1 pc(s).
Net weight	3.275
Gross weight	3.475
Customs tariff number	94039910
EAN	4028177165731
E-Number Sweden	E7239733
ECLASS 8.0	27189261

# Tender text

Component shelves for 482.6 mm (19") attachment level

Component shelves, W x D: 390 x 300 mm; made from 1.5 mm steel sheet, for network enclosures with one 482.6 mm (19") attachment level.

The component shelf has slots for preventing heat accumulation and can be loaded up to a maximum of 25 kg. The component shelf is fitted on U-pitch pattern mounting angles and the height can be adjusted linearly as per the U-pitch pattern, using the T-slot mounting angles

Material: Sheet steel

Paint finish: RAL 7035

W x D dimensions: 390 x 300 mm