

Rittal – The System.

Faster – better – everywhere.



DK 7827.560

TS installation kit, width-variable

State: 8/12/2025 (Source: [rittal.com/nz-en](https://www.rittal.com/nz-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7827.560 - TS installation kit, width-variable 482.6 mm (19")/metric in TS

Universal depth stays to which both L-shaped and cranked mounting angles may be variably mounted in the depth and width.

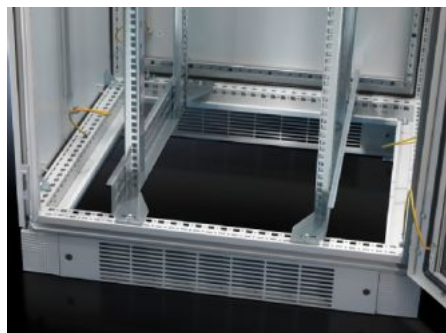

Features

Model No.	DK 7827.560
Product description	Universal depth stays to which both L-shaped and cranked mounting angles may be variably mounted in the depth and width. Installation kit for all width dimensions: Imperial mounting dimensions 19"/21"/23"/24", metric dimensions 18/20 SU
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
To fit	Enclosure type: TS 8 Depth: 1,000 mm
Load capacity	200 kg static load per level
Packs of	1 set(s)
Net weight	2.3
Gross weight	2.55
Customs tariff number	73182900
EAN	4028177616042
ECLASS 8.0	27189234

Tender text

TS divider kit, width-variable, 482.6 mm (19")/metric

For cranked and L-shaped mounting angles for all width dimensions:

imperial: 482.6 mm (19 inch) / 533.4 mm (22 inch) / 584.2 mm (23 inch) / 609.6 mm (24 inch),

metric: 485 mm (18 SU) / 535 mm (20 SU)

Dimension: D 1000 mm

Material: Sheet steel, zinc-plated, passivated

Make/model: Rittal

Type: DK-TS depth stay DK 7827560 or equivalent