


# Rittal – The System.

Faster – better – everywhere.

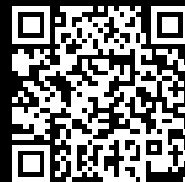

## SZ 2564.300

### Plastic gland plate

State: 07/08/2025 (Source: [rittal.com/ro-ro](https://www.rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2564.300 - Plastic gland plate with membranes, for AX

Simply pierce the plastic with a sharp object, and pull through the cable.

## Features

Model No.	SZ 2564.300
Product description	Simply pierce the plastic with a sharp object, and pull through the cable.
Material	Plastic to UL 94-V0
Colour	Similar to RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
Dimensions	Width: 534 mm Depth: 149 mm
To fit	Enclosure type: AX
Gland plate	Size: 4
Protection category to IEC 60 529	IP 66 if installed correctly
Type rating to UL 50E	Type 1 Type 12
No. of cable entries and Ø (mm) min.-max.	28 x 5-11 48 x 10-15 8 x 15-25 2 x 19-34 2 x 26-35 2 x 26-54 1 x 50-110
Packs of	1 pc(s).
Net weight	0.7
Gross weight	0.736
Customs tariff number	39269097
EAN	4028177935723

# Features

E-Number Sweden	E3465291
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

# Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------