


**Rittal – The System.**

Faster – better – everywhere.

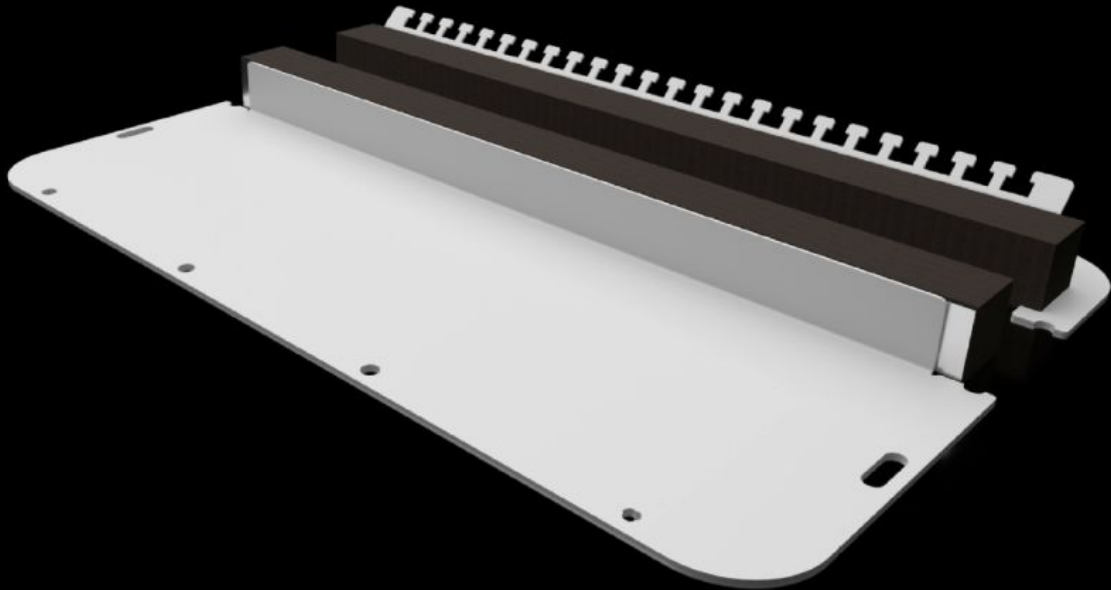

**SZ 2567.450**

**Two-part gland plate with foam  
rubber cable clamp strip**

State: 08/07/2026 (Source: [rittal.com/ro-ro](http://rittal.com/ro-ro))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2567.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

## Features

Model No.	SZ 2567.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required
Dimensions	Width: 436 mm Depth: 221 mm
To fit	Enclosure type: AX
To fit Model No.	1260.000 1339.000 1360.000 1376.000 1059.000 1091.000 1116.000 1261.000
Gland plate	Size: 7
Packs of	1 pc(s).
Net weight	1,4 kg
Gross weight	1,46 kg

# Features

PCF per pack (cradle-to-gate)	5.6 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73079100
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD 436x221 mm, for gland plate size 7