


Rittal – The System.

Faster – better – everywhere.

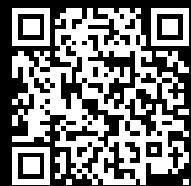

AS 4050.782

Wire end ferrules

State: 17/02/2026 (Source: rittal.com/ro-ro)

AS 4050.782 - Wire end ferrules loose

With plastic collar.

Features

| | |
|--------------------------|---|
| Model No. | AS 4050.782 |
| Product description | With plastic collar. |
| Technical specifications | Heat-resistant to 105 °C |
| Material | E-Cu, galvanic tin-plated Plastic collar: Polypropylene |
| Colour | Grey |
| Length | 8 mm |
| AWG | 12 |
| Internal diameter | 4,8 mm |
| Rittal colour code | Yes |
| For cross-section | 4 mm ² |
| Note | UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant. |
| Standards | AEH DIN 46228 |
| Delivery form | Loose |
| Packs of | 500 pc(s). |
| Net weight | 0,5 kg |
| Gross weight | 0,114 kg |
| Customs tariff number | 85369010 |
| ETIM 9 | EC000005 |
| ETIM 8 | EC000005 |
| ECLASS 8.0 | 36659290 |

Features

Product description

Wire end ferrules for wire processing, 4 mm², AWG 12, 8 mm, grey, loose, 500 pcs.

Approvals

Approvals

UL + C-UL (listed)

UR