


Rittal – The System.

Faster – better – everywhere.

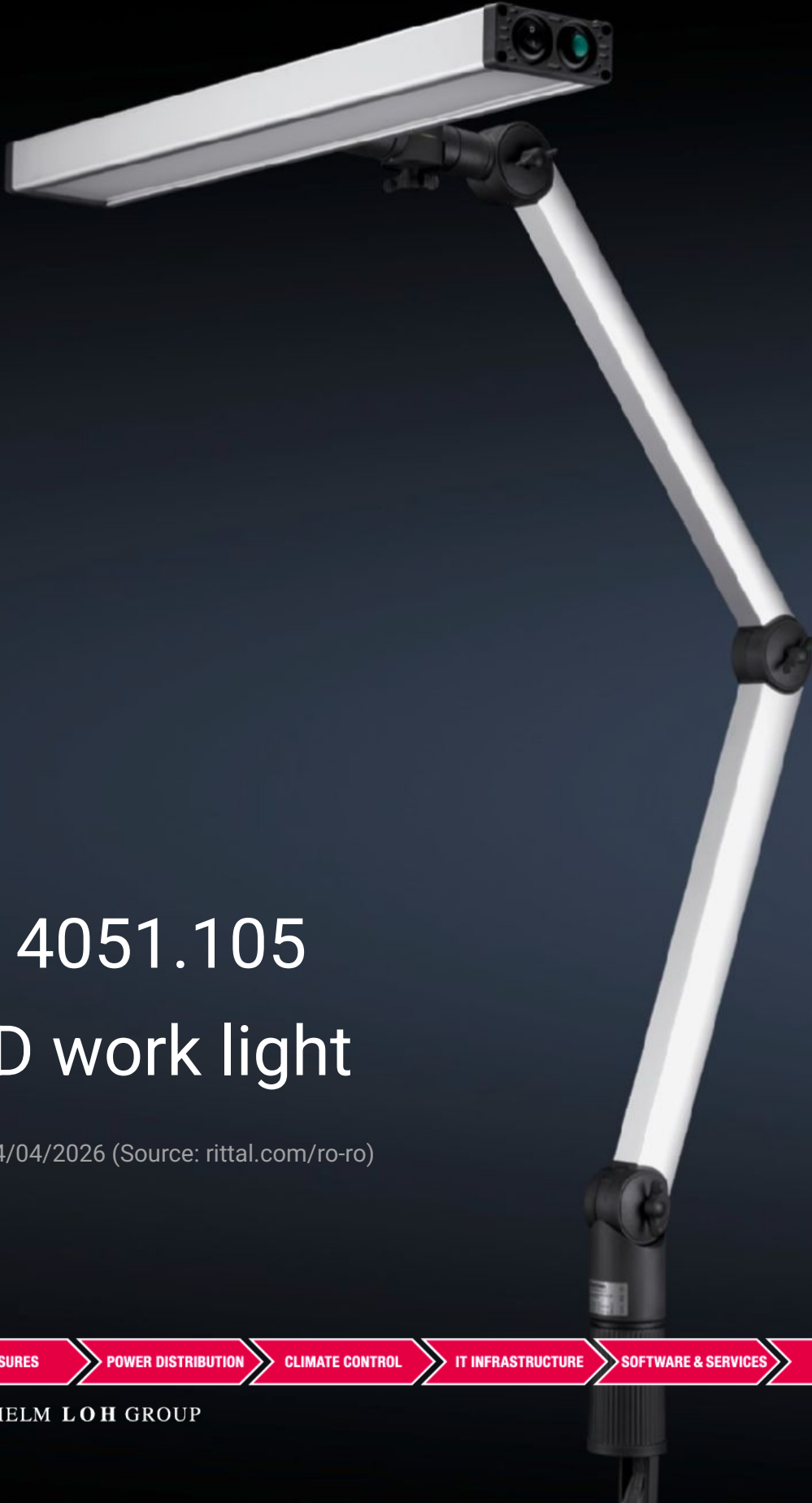

AS 4051.105 LED work light

State: 04/04/2026 (Source: rittal.com/ro-ro)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4051.105 - LED work light for WS 540

For attaching to the table top, with clamping device.



Features

Model No.	AS 4051.105
Product description	For attaching to the table top, with clamping device.
Benefits	<p>Bright, glare- and flicker-free lighting, homogeneous and shadow-free</p> <p>Selectable colour temperature between warm white, neutral white and daylight white promotes concentration and reduces symptoms of fatigue</p> <p>Excellent colour fidelity and high contrast</p> <p>Aluminium spring arm with 3D head joint, swivelling and lockable for free positioning of the light source</p>
Technical specifications	<p>Spring arm: Length 970 mm</p> <p>Colour reproduction: 94 – 98 Ra</p> <p>Transmission angle: 100°</p>
Material	<p>Light housing: Aluminium</p> <p>Glare control: Macrolon</p>
Supply includes	<p>LED work light</p> <p>Assembly parts</p>
Power consumption	26 W
Length of connection cable	3 m
Connection options	Plug-in power supply (CEE 7/16) with AC adaptor
Light	84 SMD LEDs

Features

Protection class	III (SELV)
Luminous flux	2.930 lm
To fit Model No.	4051.100
Operating temperature range	-10 °C...40 °C
Rated operating voltage	110 V - 240 V, 1~, 50 Hz/60 Hz
Dimensions	Width: 545 mm Height: 90 mm Depth: 35 mm
Packs of	1 pc(s).
Net weight	2,5 kg
Gross weight	4,2 kg
Customs tariff number	94054990
ETIM 9	EC002778
ETIM 8	EC002778
ECLASS 8.0	36629090
Product description	LED work light for WS 540, dimmable, 230 V/50 Hz